

EF7078-002 | EFDT-12HMFOC-S4-40MIO-TE



RapidFiber® EFDT Wall Mounting Fiber Box, outdoor, 12 SC/APC, HMFOC at far end, 40 m

- Designed to provide a quick and simple solution for installing fiber in small and medium sized MDU's
- Incorporates a unique fiber cable spooling system that stores up fiber cable within the enclosure
- Removes the need for field termination and extensive site survey inspections
- Weatherproof housing suitable for external environmental conditions

OBSOLETE

This product was discontinued on: February 28, 2019

Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Product Type	Fiber wall box
Product Brand	RapidFiber®
Product Series	EFDT

General Specifications

Functionality	Patching
Access	Front
Cable Color	White
Cable Type	Microcable - Loose Tube
Enclosure Color	Gray
Front Cover Type	Hinged with lock
Interface	SC/APC
Interface, stub	HMFOC
Mounting	Wall
Port, quantity	12


Dimensions

Height	264.16 mm 10.4 in
Width	179.07 mm 7.05 in

EF7078-002 | EFDT-12HMFOC-S4-40MIO-TE

Depth	71.12 mm 2.8 in
Cable Length	40 m 131.234 ft

Ordering Tree

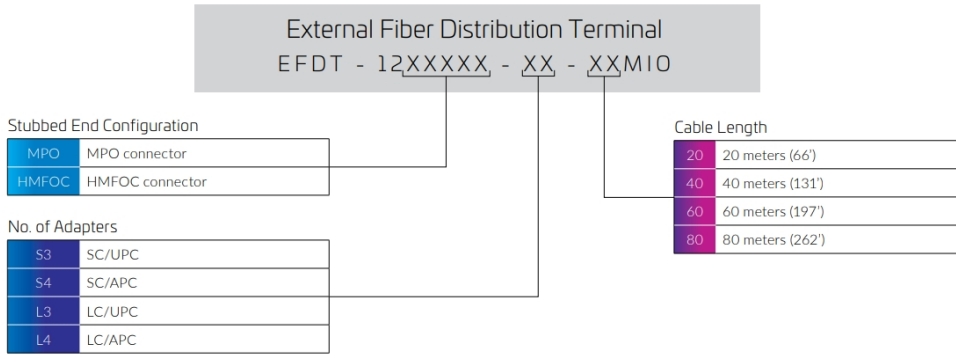

Material Specifications

Enclosure Material Type	LSZH thermoplastic
--------------------------------	--------------------

Optical Specifications

Fiber Mode	Singlemode
Fiber Type	G.657.A2
Insertion Loss, Terminal Connector, typical	0.4 dB
Return Loss, Connector, minimum	55 dB

Environmental Specifications

Environmental Space	Outdoor
----------------------------	---------

Packaging and Weights

Packaging quantity	1
Packaging Type	Box Carton

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant

UK-ROHS

Compliant

