

# UGGMWMMWAD

## Base Product



Ultra Low Loss (ULL) Singlemode MPO12 Female with Push-Pull Boot to MPO12 Female with Push-Pull Boot, Fiber Trunk Cable Assembly, 12-Fiber, Plenum

## Product Classification

<b>Regional Availability</b>	Asia   Australia/New Zealand   China   Europe   India   Latin America   Middle East/Africa   North America
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Fiber trunk cable assembly
<b>Product Brand</b>	SYSTIMAX ULL
<b>Ordering Note</b>	For additional jacket colors, please contact a CommScope Sales Representative   For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration

## General Specifications

<b>Color, boot A</b>	Black
<b>Color, connector A</b>	Yellow
<b>Color, boot B</b>	Black
<b>Color, connector B</b>	Yellow
<b>Construction Type</b>	Stranded
<b>Furcation Color</b>	Yellow
<b>Interface, Connector A</b>	MPO-12/APC Female
<b>Interface Body Style, connector A</b>	Push-pull boot
<b>Interface, Connector B</b>	MPO-12/APC Female
<b>Interface Body Style, connector B</b>	Push-pull boot
<b>Jacket Color</b>	Yellow
<b>Polarity</b>	Method B Enhanced (ULL)
<b>Fibers per Subunit, quantity</b>	12
<b>Total Fibers, quantity</b>	12

## Dimensions


<b>Cable Assembly Length Range (m)</b>	3 – 999
--	---------

# UGGMWMMWAD

**Cable Assembly Length Range (ft)**

10 – 999

## Ordering Tree

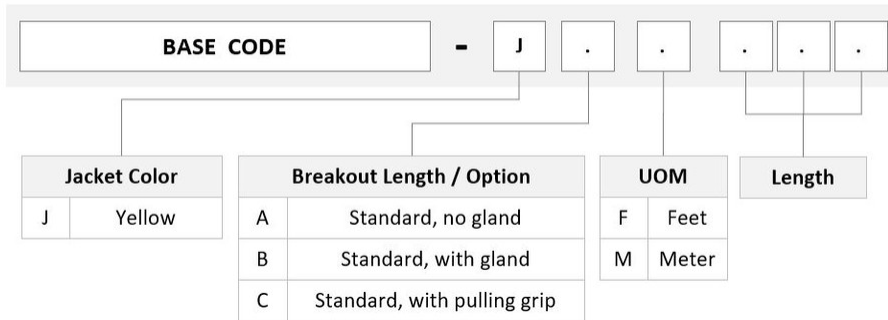

## Mechanical Specifications

**Cable Retention Strength, maximum**

11.24 lb @ 0 ° | 4.40 lb @ 90 °

## Optical Specifications

**Fiber Mode**

Singlemode

**Fiber Type**

G.657.A2, TeraSPEED®

## Environmental Specifications

**Operating Temperature**

-10 °C to +60 °C (+14 °F to +140 °F)

**Environmental Space**

Indoor | Plenum

## Regulatory Compliance/Certifications

**Agency**

**Classification**

ISO 9001:2015

Designed, manufactured and/or distributed under this quality management system

## Included Products

460202380

– MPO8/12 ULL Female, Singlemode, Yellow, Push-Pull, 3mm

760237963

– Fiber indoor cable, Plenum for MPO Trunks, 12 fiber, Singlemode G.657.A2/B2, Feet jacket marking, Yellow jacket color

P-012-MP-8G1-F12YL