


FPCC-7EYP

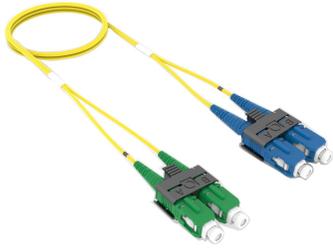

Fiber Optic Patch Cord, duplex, singlemode, 1.2 mm OFNP jacket, SC /UPC-SC/APC, yellow

- 1.2 mm diameter cable provides a 65% space savings over commonly used 2.0 mm cable
- 1.2 mm diameter fiber patch cords use Reduced Bend Radius (RBR) fiber cable
- Typically used in environments where space constraints and cable routing prove most challenging

Product Classification

Regional Availability	Europe Latin America Middle East/Africa North America
Product Type	Fiber patch cord, duplex
Product Series	FPCC

General Specifications


Connector A, quantity	1
Color, boot A	Blue
Color, connector A	Blue
Connector B, quantity	1
Color, boot B	Blue
Color, connector B	Blue
Interface, Connector A	SC/UPC
Interface, Connector B	SC/APC
Jacket Color	Yellow
Total Fibers, quantity	2
Transmission Standards	TIA/EIA-604 FOCIS-3

Dimensions

Diameter Over Jacket	1.2 mm 0.047 in
-----------------------------	-------------------

Ordering Tree

FPCC-7EYP

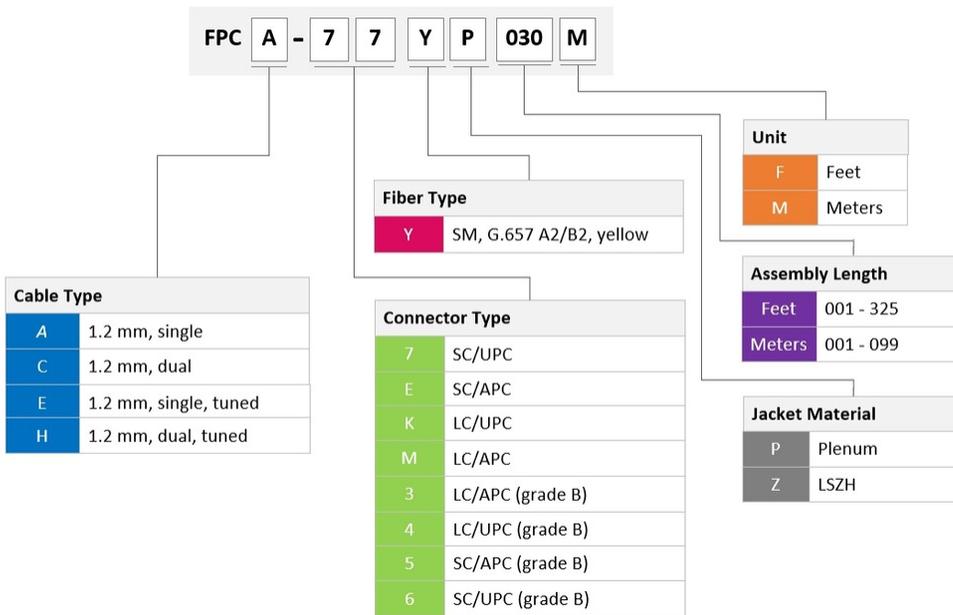

Optical Specifications

Fiber Mode	Singlemode
Fiber Type	G.657.A2/B2
Insertion Loss, maximum, connector A	0.2 dB
Insertion Loss, maximum, connector B	0.2 dB
Return Loss, minimum, connector A	55 dB
Return Loss, minimum, connector B	55 dB

Environmental Specifications

Environmental Space	Plenum
Qualification Standards	GR-326 CORE GR-409 GR-449-CORE

Packaging and Weights

Packaging quantity	1
---------------------------	---