

IFEB20, Indoor Fiber Optic Wall mount Enclosure, Splice / Patch, LC/APC Pigtails and Adapters (32), Single Element Slim trays(8) Smouv, Feeder cable seal 2x15mm and 16x7mm drop seal, RAL 9010

- Compact, wall mountable fiber enclosures for indoor use
- Specifically designed for fast FTTH deployment and easy customer connection
- Configurable as splice only or connectorized solution
- Multiple and modular wrap around cable port sealing options to suit a wide range of cables
- Easy intergration of 900µm connectorised or 250µm splice splitters
- Single Element (SE), Single Slim Element (SLE) or Single Circuit (SC) tray options - Smouv and ANT
- Powered by NOVUX™

## Product Classification

<b>Regional Availability</b>	EMEA
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Fiber wall box
<b>Product Series</b>	IFEB-20

## General Specifications

<b>Functionality</b>	Patching   Splicing
<b>Access</b>	Front
<b>Adapter Ports, quantity</b>	32
<b>Cable Ports, quantity</b>	2
<b>Drop Port, quantity</b>	16
<b>Enclosure Color</b>	Pure White (RAL 9010)
<b>Front Cover Type</b>	Snap-on cover
<b>Interface</b>	LC/APC
<b>Pigtails Included, quantity</b>	32
<b>Splice Tray Construction</b>	SLE (Slim element tray for up to 12 primary coated fibers)
<b>Splicing Capacity, maximum</b>	96
<b>Splicing Type</b>	SMOUV


## Dimensions

<b>Height</b>	270 mm   10.63 in
---------------	-------------------


# 760259791 | IFEB-20WB4032C08SDFN000

<b>Height, with cover</b>	348 mm   13.701 in
<b>Width</b>	213 mm   8.386 in
<b>Depth</b>	87 mm   3.425 in

## Dimension Drawing

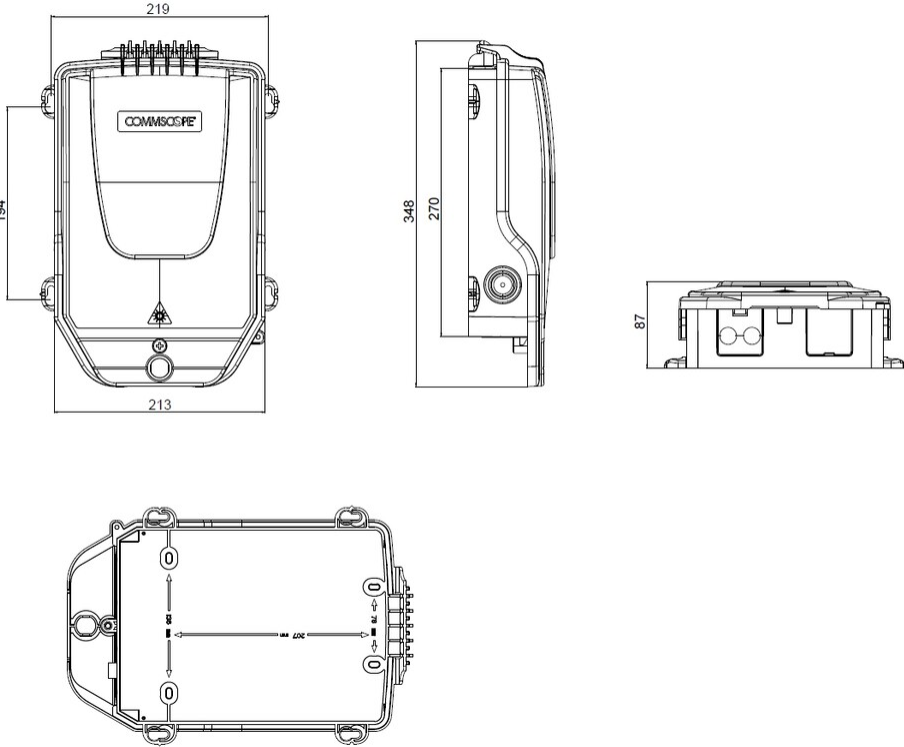

## Ordering Tree

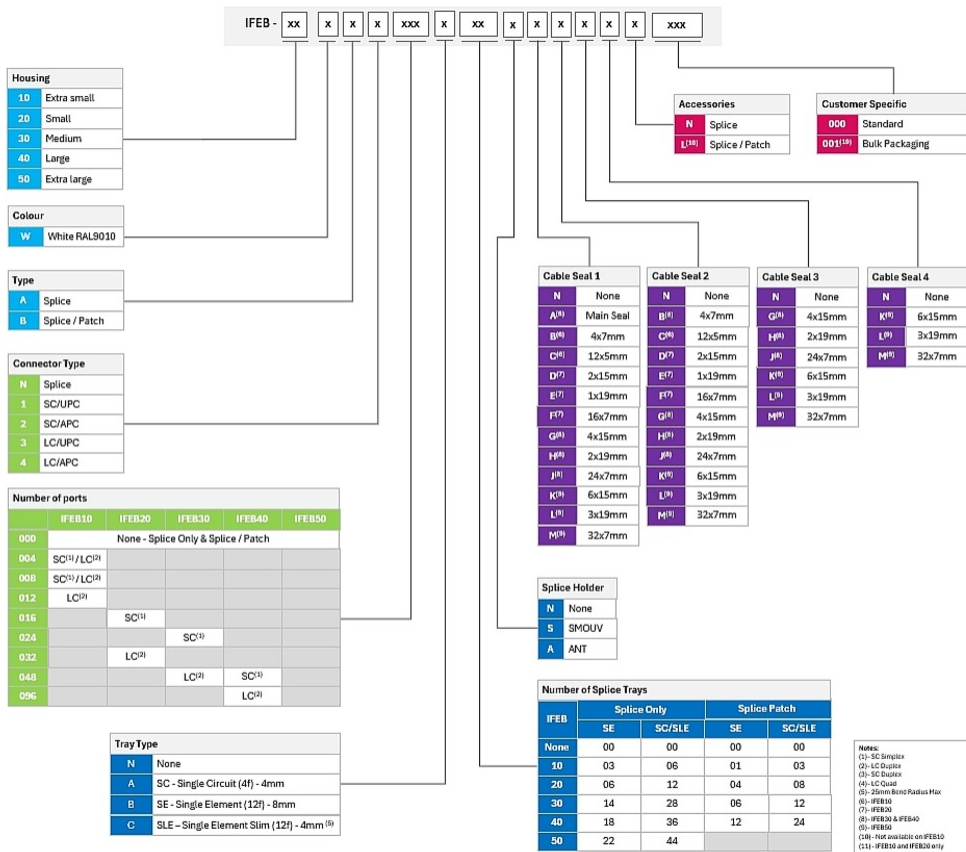

## Environmental Specifications

<b>Installation temperature</b>	-5 °C to +45 °C (+23 °F to +113 °F)
<b>Operating Temperature</b>	-10 °C to +60 °C (+14 °F to +140 °F)
<b>Environmental Space</b>	Indoor
<b>Flammability Rating</b>	UL 94 V-0
<b>Qualification Standards</b>	IEC 60529, IP50   IEC 61753-1 Ed.2 2018 - Category C

## Packaging and Weights

<b>Included</b>	Adapters (16)   Box (1)   Drop Seal, 16x7 (1)   Feeder Seal, 2x15 (1)   SLE Smouv trays (8)
<b>Packaging quantity</b>	1
<b>Packaging Type</b>	Box

## Regulatory Compliance/Certifications

<b>Agency</b>	<b>Classification</b>
---------------	-----------------------

760259791 | IFEB-20WB4032C08SDFNNN000

---

CHINA-ROHS

Below maximum concentration value

REACH-SVHC

Compliant as per SVHC revision on [www.commscope.com/ProductCompliance](http://www.commscope.com/ProductCompliance)

ROHS

Compliant

UK-ROHS

Compliant

