


FPWLCCLCAD

Base Product

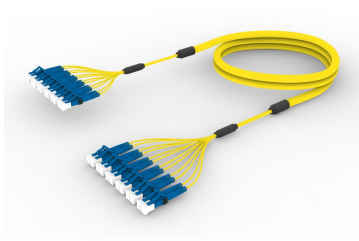

SingleMode LC/UPC to LC/UPC, InstaPATCH® 360 Armored Ruggedized Fiber Fanout Cable Assembly, 12-Fiber, Low Smoke Zero Halogen (LSZH)

Product Classification

| | |
|------------------------------|---|
| Regional Availability | Asia Australia/New Zealand China Europe India Latin America Middle East/Africa North America |
| Portfolio | CommScope® |
| Product Type | Ruggedized fanout |
| Product Brand | SYSTIMAX InstaPATCH® 360 |
| Ordering Note | For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration Not available in the United States or Canada |

General Specifications

| | |
|-------------------------------------|----------------|
| Color, boot A | Blue |
| Color, connector A | Blue |
| Color, boot B | Blue |
| Color, connector B | Blue |
| Construction Type | Stranded |
| Furcation Color | Yellow |
| Interface, Connector A | LC/UPC |
| Interface, Connector B | LC/UPC |
| Jacket Color | Yellow |
| Polarity | Pairs, flipped |
| Fibers per Subunit, quantity | 12 |
| Total Fibers, quantity | 12 |

Dimensions


| | |
|--|---------|
| Cable Assembly Length Range (m) | 3 – 305 |
|--|---------|

FPWLCLCAD

Cable Assembly Length Range (ft)

8 – 999

Ordering Tree

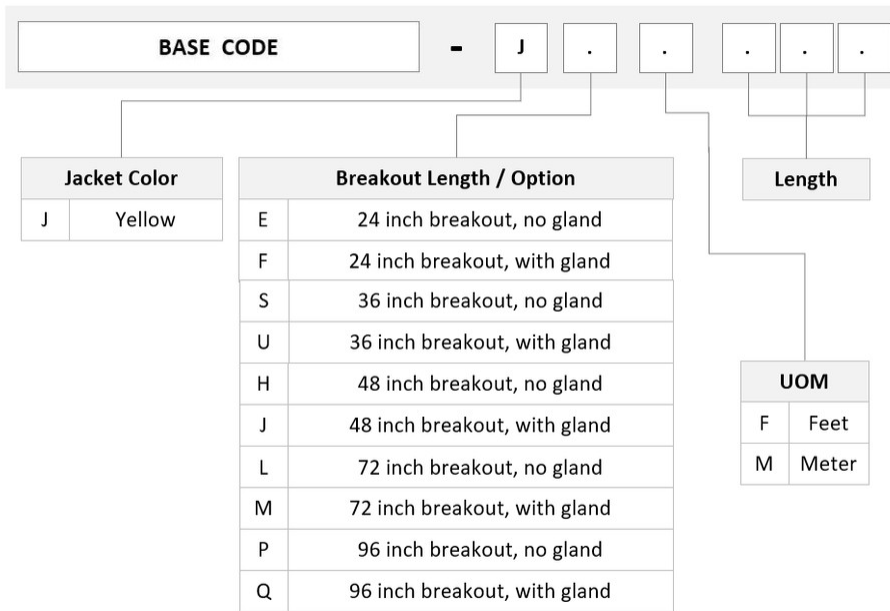

Mechanical Specifications

Cable Retention Strength, maximum 11.24 lb @ 0 ° | 4.40 lb @ 90 °

Optical Specifications

Fiber Mode Singlemode

Fiber Type G.652.D | G.657.A1, TeraSPEED®

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)

Environmental Space Dual Rated LSZH/Riser | Indoor

Packaging and Weights

Packaging quantity 1

Included Products

FPWLCLCAD

- 760256101
N-012-MZ-8G1-F12YL/20T/B2 – Fiber indoor cable, Riser/LSZH rated, MPO Trunk, interlocking aluminum armored, Singlemode G.657.A2/B2, 12 fiber, Feet jacket marking, Yellow jacket color, B2ca flame rating
- 860655488 – LC/UPC Connector, Singlemode, Blue