

FMT-DTR070A00-A24P

FMT Fiber Termination/Splice Panel, with sliding tray, 24 SC/UPC, singlemode, 1RU, 19 in, putty white



Product Classification

| | |
|------------------------------|-------------------------------|
| Regional Availability | Latin America North America |
| Portfolio | CommScope® |
| Product Type | Fiber patch/splice panel |
| Product Series | FMT |

General Specifications


| | |
|---------------------------------|-----------------------|
| Functionality | Patching Splicing |
| Body Style | Symmetrical |
| Color | Black |
| Color, front | Putty white |
| Interface, front | SC |
| Interface Feature, front | Standard |
| Rack Type | EIA 19 in EIA 23 in |
| Rack Units | 1 |
| Shelf Movement | Sliding |
| Total Ports, quantity | 24 |

Dimensions

| | |
|---------------|----------------------|
| Height | 44.45 mm 1.75 in |
| Width | 482.6 mm 19 in |
| Depth | 279.91 mm 11.02 in |

Ordering Tree

FMT-DTR070A00-A24P

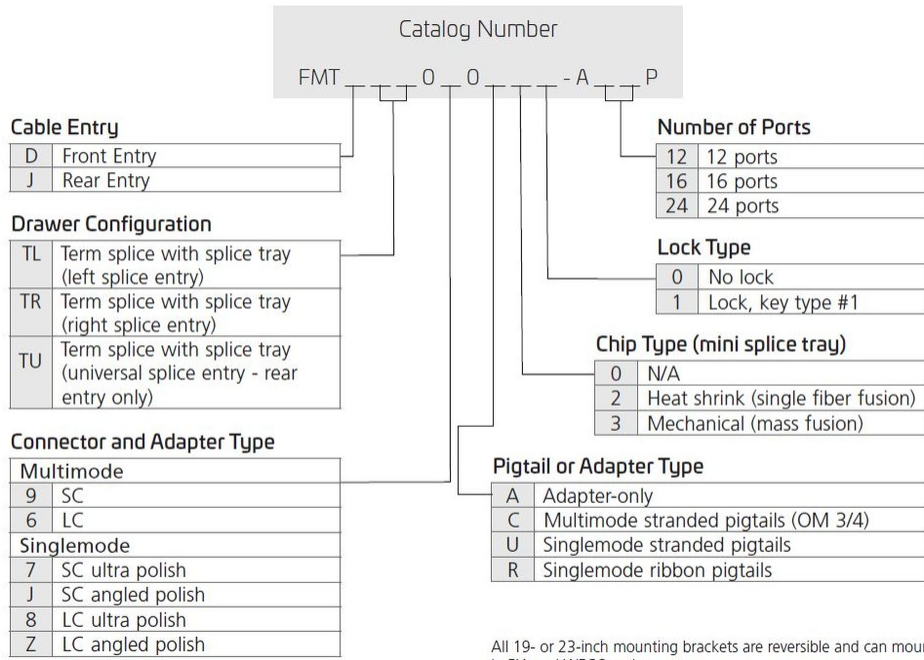

Material Specifications

| | |
|----------------------|---------------|
| Finish | Powder coated |
| Material Type | Steel |

Optical Specifications

| | |
|-------------------|------------|
| Fiber Mode | Singlemode |
|-------------------|------------|

Packaging and Weights

| | |
|---------------------------|-------------------|
| Included | Mounting hardware |
| Packaging quantity | 1 |

Regulatory Compliance/Certifications

| Agency | Classification |
|------------|--|
| CHINA-ROHS | Below maximum concentration value |
| REACH-SVHC | Compliant as per SVHC revision on www.commscope.com/ProductCompliance |
| ROHS | Compliant |

