

# FMT-JN2A80160-A24P

---

FMT Fiber Termination Panel, 24 LC/UPC, singlemode, 1RU, 19 in, putty white, pre-terminated with IFC cable, 16 meters, stub tail at far end



## Product Classification

|                              |                                   |
|------------------------------|-----------------------------------|
| <b>Regional Availability</b> | Latin America   North America     |
| <b>Portfolio</b>             | CommScope®                        |
| <b>Product Type</b>          | Fiber patch panel, with IFC cable |
| <b>Product Series</b>        | FMT                               |

## General Specifications


|                              |                       |
|------------------------------|-----------------------|
| <b>Functionality</b>         | Patching              |
| <b>Body Style</b>            | Symmetrical           |
| <b>Cable Stub Type</b>       | IFC                   |
| <b>Color</b>                 | Black                 |
| <b>Color, front</b>          | Putty white           |
| <b>Interface, front</b>      | LC/UPC                |
| <b>Interface, rear</b>       | Stub tail             |
| <b>Rack Type</b>             | EIA 19 in   EIA 23 in |
| <b>Rack Units</b>            | 1                     |
| <b>Shelf Movement</b>        | Sliding               |
| <b>Total Ports, quantity</b> | 24                    |

## Dimensions

|                     |                      |
|---------------------|----------------------|
| <b>Height</b>       | 44.45 mm   1.75 in   |
| <b>Width</b>        | 482.6 mm   19 in     |
| <b>Depth</b>        | 279.91 mm   11.02 in |
| <b>Cable Length</b> | 16 m   52.493 ft     |

# FMT-JN2A80160-A24P

## Ordering Tree

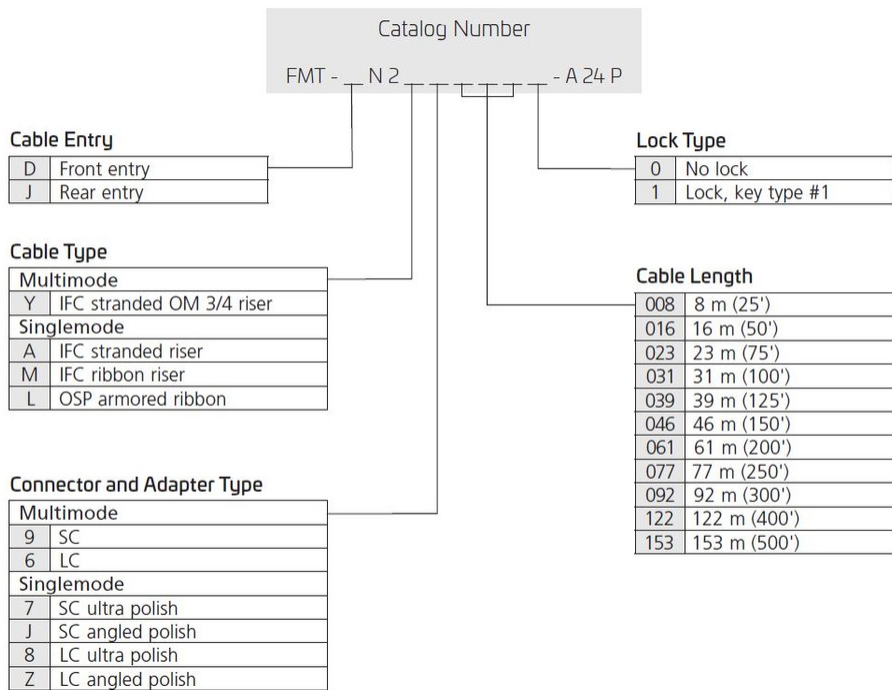

## Material Specifications

**Finish** Powder coated

**Material Type** Steel

## Optical Specifications

**Fiber Mode** Singlemode

## Packaging and Weights

**Packaging quantity** 1

## Regulatory Compliance/Certifications

| Agency     | Classification  |
|------------|---|
| CHINA-ROHS | Above maximum concentration value   |
| REACH-SVHC | Compliant as per SVHC revision on <a href="https://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a> |
| ROHS       | Compliant/Exempted  |
| UK-ROHS    | Compliant   |

