

FMT-JTU082U20-A24P

FMT Fiber Termination/Splice Panel, with sliding tray, 24 LC/UPC, singlemode, 1RU, 19 in, white



Product Classification

Regional Availability	Latin America North America
Portfolio	CommScope®
Product Type	Fiber patch/splice panel
Product Series	FMT

General Specifications


Functionality	Patching Splicing
Body Style	Symmetrical
Color	Black
Color, front	Putty white
Interface, front	LC
Interface Feature, front	Standard
Rack Type	EIA 19 in EIA 23 in
Rack Units	1
Shelf Movement	Sliding
Total Ports, quantity	24

Dimensions

Height	44.45 mm 1.75 in
Width	482.6 mm 19 in
Depth	279.91 mm 11.02 in

Ordering Tree

FMT-JTU082U20-A24P

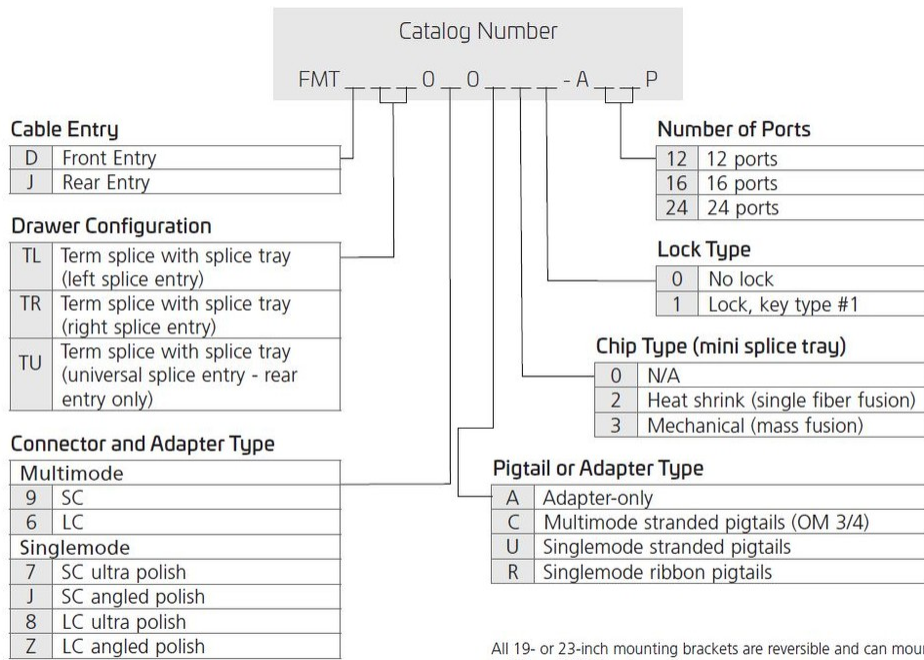

All 19- or 23-inch mounting brackets are reversible and can mount in EIA and WECCO racks.

Material Specifications

Finish	Powder coated
Material Type	Steel

Optical Specifications

Fiber Mode	Singlemode
-------------------	------------

Packaging and Weights

Included	Mounting hardware
Packaging quantity	1

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant/Exempted

