

212855-000 | OCFPS1U-DMQ1204L2-SUBU23



OCFPS Fiber Optic DWDM Panel, mux, 40 channels, 1561.42 nm starting wavelength, 100 GHz channel spacing, upgrade port, LC/APC, 1U, 19 in, gray

Product Classification

Regional Availability	North America
Portfolio	CommScope®
Product Type	DWDM patch panel
Product Series	OCFPS

General Specifications

Device Type	Patch panel
Functionality	Multiplexing
Technology Type	Thin film filter (TFF)
Circuits, quantity	1
Distribution Type	40-channel DWDM
Interface, front	LC/APC
Multiplexers, quantity	1
Port Type, optional	Upgrade port


Dimensions

Height	43.5 mm 1.713 in
Width	440 mm 17.323 in
Depth	210 mm 8.268 in

Ordering Tree

212855-000 | OCFPS1U-DMQ1204L2-SUBU23

OCFPS 1U - X X X X X X

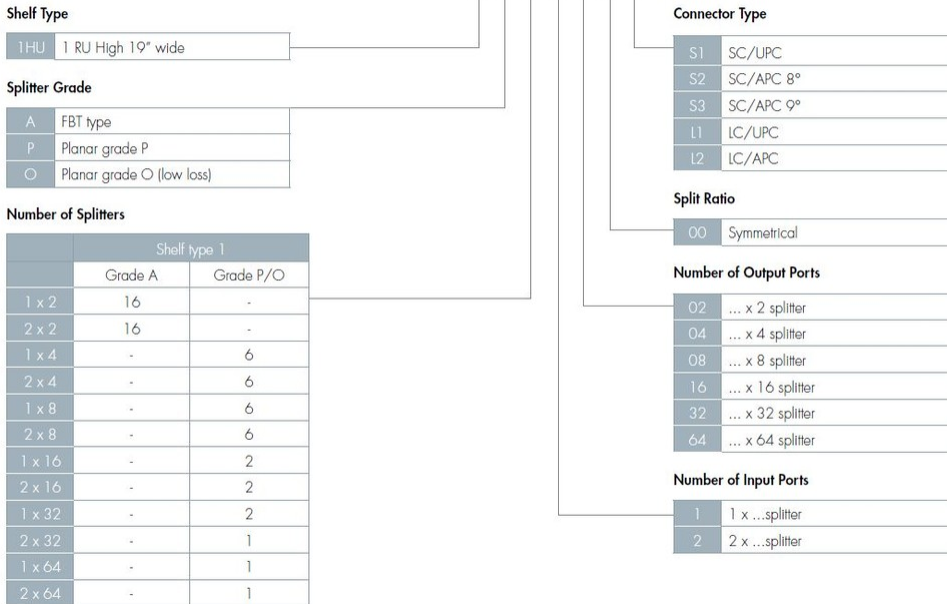

Optical Specifications

Channel Spacing	100 GHz
Starting Wavelength	1,561.42 nm

Packaging and Weights

Packaging quantity	1
---------------------------	---

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant

