


# FD3-MN432J00LABCAB

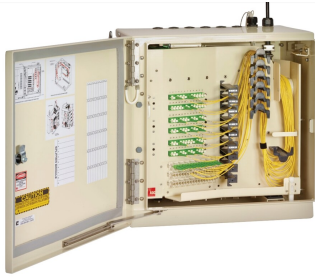

IFDH 3000 Indoor Fiber Distribution Hub, 432F, SC/APC, riser I/O LT 50' stub, 24F 100' stub feeder cable

## Product Classification

<b>Regional Availability</b>	North America
<b>Product Type</b>	Fiber distribution hub
<b>Product Series</b>	IFDH 3000

## General Specifications

<b>Access</b>	Front
<b>Adapters, quantity</b>	432
<b>Cable Type</b>	Indoor/outdoor - Stranded
<b>Color</b>	Putty white
<b>Distribution Cables, quantity</b>	3
<b>Fibers per Distribution Cable, quantity</b>	144
<b>Fibers per Feeder Cable, quantity</b>	24
<b>Front Door Type</b>	Single hinged
<b>Interface</b>	SC/APC
<b>Mounting</b>	Wall
<b>Port, quantity</b>	432
<b>Splitter Slots, quantity</b>	18

## Dimensions

<b>Height</b>	990.6 mm   39 in
<b>Width</b>	358.1 mm   14.098 in
<b>Depth</b>	368.3 mm   14.5 in
<b>Cable Length</b>	30.48 m   100 ft
<b>Enclosure Size</b>	Large

## Material Specifications

# FD3-MN432J00LABCAB

---

**Finish** Powder coated

**Material Type** Steel

## Optical Specifications

**Fiber Mode** Singlemode

## Environmental Specifications

**Environmental Space** Indoor

## Packaging and Weights

**Packaging quantity** 1

## Regulatory Compliance/Certifications

### Agency

### Classification

CHINA-ROHS

Above maximum concentration value

REACH-SVHC

Compliant as per SVHC revision on [www.commscope.com/ProductCompliance](http://www.commscope.com/ProductCompliance)

ROHS

Compliant/Exempted

UK-ROHS

Compliant/Exempted

