

# TFP-5TPC8-121B

---

TFP Fiber Termination/Splice Panel, 144 SC/UPC, preterminated with pigtails, singlemode, 5RU, 19 in, black

## Product Classification

|                              |                               |
|------------------------------|-------------------------------|
| <b>Regional Availability</b> | Latin America   North America |
| <b>Portfolio</b>             | CommScope®                    |
| <b>Product Type</b>          | Fiber patch/splice panel      |
| <b>Product Series</b>        | TFP                           |

## General Specifications


|                                  |                                      |
|----------------------------------|--------------------------------------|
| <b>Functionality</b>             | Patching   Splicing                  |
| <b>Body Style</b>                | Symmetrical                          |
| <b>Color</b>                     | Black                                |
| <b>Color, front</b>              | Black                                |
| <b>Interface, front</b>          | SC/UPC                               |
| <b>Patch Cord Entry Location</b> | Front, left side   Front, right side |
| <b>Rack Type</b>                 | EIA 19 in   EIA 23 in                |
| <b>Rack Units</b>                | 5                                    |
| <b>Shelf Movement</b>            | Fixed                                |
| <b>Total Ports, quantity</b>     | 144                                  |

## Dimensions

|               |                      |
|---------------|----------------------|
| <b>Height</b> | 222.25 mm   8.75 in  |
| <b>Width</b>  | 482.6 mm   19 in     |
| <b>Depth</b>  | 399.29 mm   15.72 in |

## Ordering Tree

# TFP-5TPC8-121B

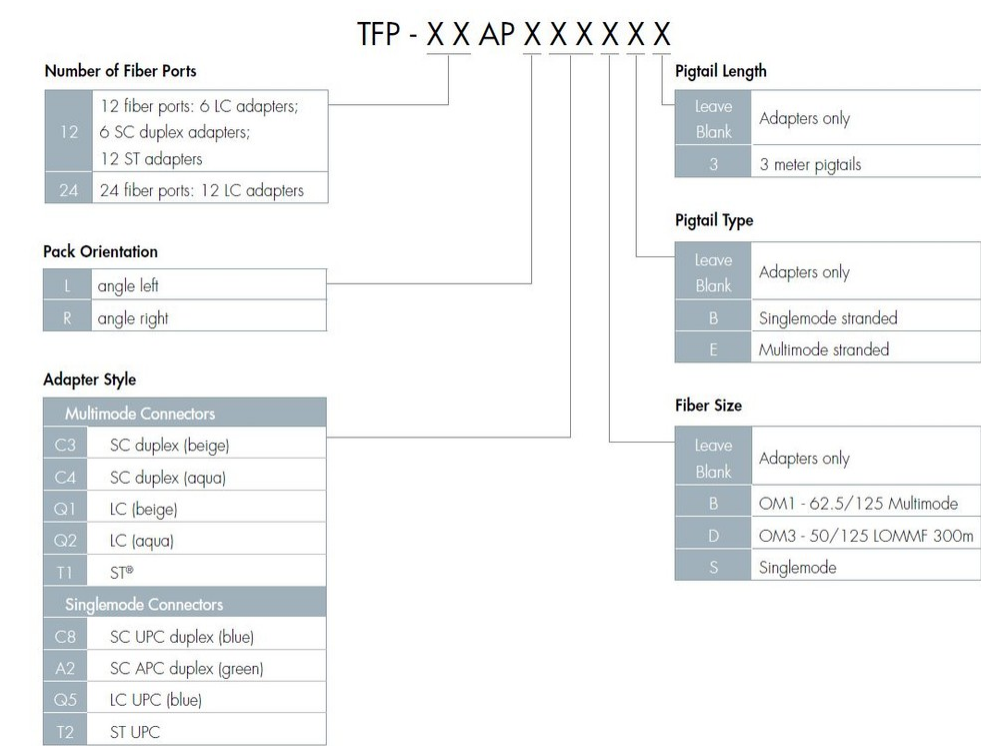

## Material Specifications

|               |               |
|---------------|---------------|
| Finish        | Powder coated |
| Material Type | Steel         |

## Optical Specifications

|            |            |
|------------|------------|
| Fiber Mode | Singlemode |
|------------|------------|

## Environmental Specifications

|                       |                                      |
|-----------------------|--------------------------------------|
| Operating Temperature | -40 °C to +85 °C (-40 °F to +185 °F) |
| Storage Temperature   | -40 °C to +85 °C (-40 °F to +185 °F) |

## Packaging and Weights

|                    |                     |
|--------------------|---------------------|
| Included           | Mounting hardware   |
| Packaging quantity | 1                   |
| Weight, net        | 7.194 kg   15.86 lb |

## Regulatory Compliance/Certifications

# TFP-5TPC8-121B

---

| Agency     | Classification   |
|------------|--|
| CHINA-ROHS | Above maximum concentration value  |
| REACH-SVHC | Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a> |
| ROHS       | Compliant/Exempted   |
| UK-ROHS    | Compliant/Exempted   |

