



FACT® Fiber Optic Splice Panel, gray, 2E high, loaded with 16 trays for holding up to 12 ANT type splices per tray

- Designed for use with the all-purpose all-front-access FIST-GR3 fiber frames supporting up to 2,688 LC or 1,344 SC connections in a single frame
- Reduced installation and maintenance time via the toolless snap-on design supporting both interconnect and cross-connect applications
- Flexible customization enabled by 4 chassis types (patch-only, patch-splice, pre-cabled and splice-only) to support all ODF applications
- High density through the single FACT element height (1E) being 30% less tall compared to the industry standard panel height (1HU)

## Product Classification

|                              |   |
|------------------------------|---|
| <b>Regional Availability</b> | Asia   Australia/New Zealand   EMEA   Latin America   North America |
| <b>Portfolio</b>             | CommScope®  |
| <b>Product Type</b>          | Fiber splice panel  |
| <b>Product Brand</b>         | FACT®   |
| <b>Product Series</b>        | FACT  |

## General Specifications

|                                   |                                       |
|-----------------------------------|---------------------------------------|
| <b>Functionality</b>              | Splicing                              |
| <b>Application</b>                | Compatible with FIST-GR3-style frames |
| <b>Body Style</b>                 | Symmetrical                           |
| <b>Color</b>                      | Gray                                  |
| <b>Color, front</b>               | Gray                                  |
| <b>Growth Configuration</b>       | Fully loaded                          |
| <b>Interface, front</b>           | Unloaded                              |
| <b>Patching Capacity, maximum</b> | 0                                     |
| <b>Rack Type</b>                  | EIA 19 in                             |
| <b>Rack Units</b>                 | 1.4                                   |
| <b>Shelf Movement</b>             | Sliding                               |
| <b>Splicing Capacity, maximum</b> | 192                                   |
| <b>Splicing Type</b>              | ANT                                   |
| <b>Total Ports, quantity</b>      | 0                                     |


# 760239964 | FACT-2ESPLA12

**Transmission Standards** ETSI EN 300 019-1-3 | IEC 61300-3-30

## Dimensions

**Height** 61.9 mm | 2.437 in  
**Width** 524 mm | 20.63 in  
**Depth** 283 mm | 11.142 in

## Ordering Tree

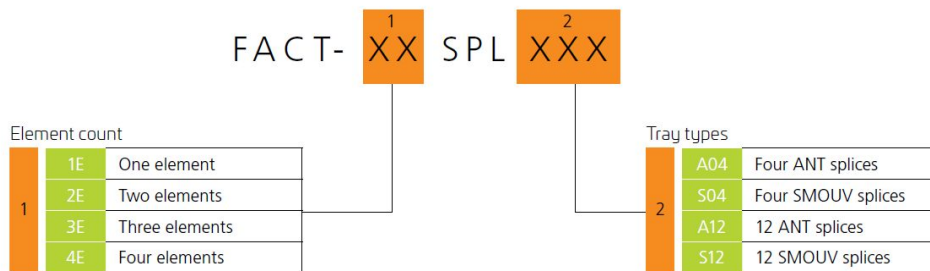

## Environmental Specifications

**Operating Temperature** -40 °C to +70 °C (-40 °F to +158 °F)  
**Storage Temperature** -20 °C to +85 °C (-4 °F to +176 °F)  
**Flammability Rating** UL 94 V-0

## Packaging and Weights

**Included** Mounting hardware  
**Packaging quantity** 1

## Regulatory Compliance/Certifications

| Agency        | Classification   |
|---------------|--|
| CHINA-ROHS    | Below maximum concentration value  |
| ISO 9001:2015 | Designed, manufactured and/or distributed under this quality management system   |
| REACH-SVHC    | Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a> |
| ROHS          | Compliant  |
| UK-ROHS       | Compliant/Exempted   |



