


# 760238894 | EHD12-DM-24LC-SM-B-ULLM

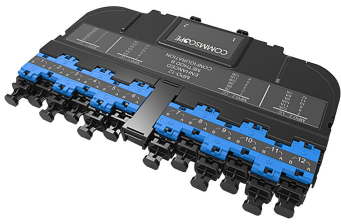

EHD ULL Singlemode MPO-12 distribution module, 24LC to 2x12f MPOs pinned, dust plugs

## Product Classification

<b>Regional Availability</b>	Asia   Australia/New Zealand   EMEA   Latin America   North America
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Fiber module
<b>Product Brand</b>	SYSTIMAX ULL
<b>Product Series</b>	EHD

## General Specifications

<b>Functionality</b>	Breakout
<b>Color, front</b>	Blue
<b>Color, rear</b>	Gray
<b>Interface, front</b>	LC/UPC
<b>Interface, rear</b>	MPO
<b>Interface Feature, rear</b>	Key up/up   Pinned
<b>Polarity</b>	Method B Enhanced (ULL)
<b>Shuttered</b>	No
<b>Total Fibers, quantity</b>	24

## Dimensions

<b>Height</b>	12.45 mm   0.49 in
<b>Width</b>	169.67 mm   6.68 in
<b>Depth</b>	115.32 mm   4.54 in

## Optical Specifications

<b>Fiber Mode</b>	Singlemode
-------------------	------------

**Fiber Type** OS2  
**Insertion Loss, maximum** 0.6 dB

## Environmental Specifications

**Qualification Standards** IEC 61753-1 | TIA-568.3-D  
**Safety Standard** CE | CSA | UL

## Packaging and Weights

**Packaging quantity** 1  
**Weight, net** 0.136 kg | 0.3 lb

## Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant
UK-ROHS	Compliant

