


663351-000 | XAGA550L-B1-300/48-M463

XAGA® 550L Copper Closure, unpressurized, heat shrink, 17 inch sheath opening, 3 inch splice bundle diameter

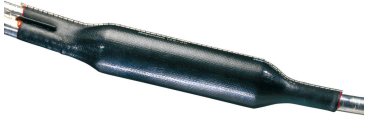

- Full range of closures to suit all copper cable sizes
- High performance heat-shrinkable closure for both maintenance and new constructions
- Suitable for use with all standard copper connector systems

OBSOLETE

This product was discontinued on: June 30, 2022

Product Classification

| | |
|------------------------------|-----------------------------------|
| Regional Availability | Latin America North America |
| Product Type | Unpressurized heat shrink closure |
| Product Brand | XAGA® |
| Product Series | XAGA 550L |


General Specifications

| | |
|--------------------------------|---|
| Application | For use with Polyethylene and metal jacketed cables |
| Branch-off Clip | To be ordered separately |
| Cable Capacity, maximum | 3 |
| Cable Sealing Type | Hotmelt adhesive |
| Closure Style | In-line |
| Color | Black |
| Mounting | Duct Manhole |
| Splice Protection Type | Metal canister |

Dimensions

| | |
|--|--------------------|
| Single Cable Diameter, minimum | 12.19 mm 0.48 in |
| Splice Bundle Diameter, maximum | 76.2 mm 3 in |
| Sheath Opening, nominal | 431.8 mm 17 in |

Dimension Drawing

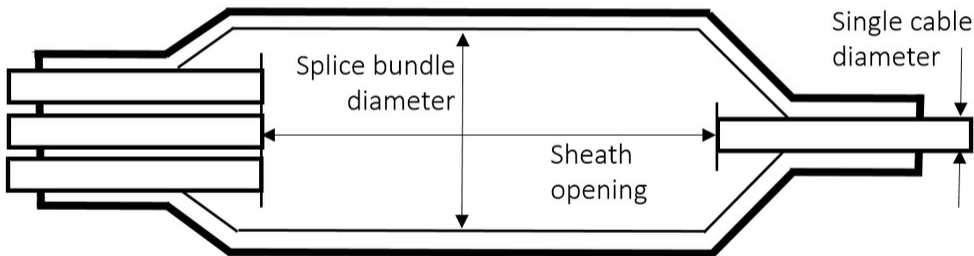

Material Specifications

Material Type Fiber-reinforced multi-layer sealing sleeve

Environmental Specifications

Environmental Space Aerial | Below ground | Buried

Packaging and Weights

Included Abrasive strip | Aluminum closing strip | Aluminum foil | Cleaning tissues | Flexible stainless steel channels | Heatshrinkable sleeve | Metal canister | Shield continuity wire | Underclips | Valve hardware

Packaging quantity 1

Packaging Type Bag | Carton

Regulatory Compliance/Certifications

Agency

CHINA-ROHS

REACH-SVHC

ROHS

Classification

Below maximum concentration value

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

Compliant

