


# 760242109 | PNL-CS-24LCV-PT

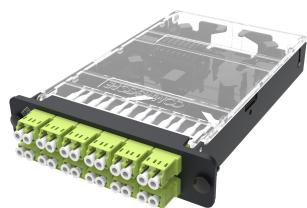

Standard Density (SD) splicing cassette 24LC OM5, 900#m

## Product Classification

<b>Regional Availability</b>	Asia   Australia/New Zealand   EMEA   Latin America   North America
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Fiber cassette with pigtails

## General Specifications

<b>Adapter Color</b>	Lime green
<b>Interface, front</b>	LC/UPC
<b>Interface, rear</b>	Stranded pigtail
<b>Total Fibers, quantity</b>	24
<b>Total Ports, quantity, front</b>	12

## Dimensions

<b>Height</b>	28.956 mm   1.14 in
<b>Width</b>	104.648 mm   4.12 in
<b>Depth</b>	165.354 mm   6.51 in
<b>Pigtail Length</b>	1.5 m   4.921 ft

## Optical Specifications

<b>Fiber Mode</b>	Multimode
<b>Fiber Type</b>	OM5, LazrSPEED® wideband
<b>Insertion Loss, typical</b>	0.3 dB

## Environmental Specifications

<b>Safety Standard</b>	UL
------------------------	----

## Packaging and Weights

<b>Packaging quantity</b>	1
---------------------------	---

## Regulatory Compliance/Certifications

**Agency**

ISO 9001:2015

**Classification**

Designed, manufactured and/or distributed under this quality management system