


760242688 | PNL-CS-12LCW-RPT

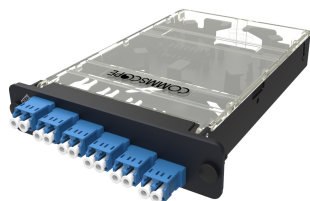

TeraSPEED® Splicing cassette, OS2, 12 LC/UPC , Ribbon

Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Portfolio	CommScope®
Product Type	Fiber cassette with ribbon pigtail
Product Brand	TeraSPEED®

General Specifications

Adapter Color	Blue
Interface, front	LC/UPC
Interface, rear	Ribbon pigtail
Total Fibers, quantity	12
Total Ports, quantity, front	6

Dimensions

Height	28.956 mm 1.14 in
Width	104.648 mm 4.12 in
Depth	165.354 mm 6.51 in
Pigtail Length	1.5 m 4.921 ft

Optical Specifications

Fiber Mode	Singlemode
Fiber Type	G.652.D and G.657.A1, TeraSPEED® OS2
Insertion Loss, typical	0.25 dB
Return Loss, minimum	50 dB

Environmental Specifications

Safety Standard	UL
------------------------	----

Packaging and Weights

Packaging quantity 1

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant

