

FL2-C420048PW-4A00

FL2000 Fiber Termination/Splice Panel, pre-terminated with pigtails, 48 FC/UPC, singlemode, 5RU, 19 in, putty white

OBSOLETE

This product was discontinued on: March 1, 2018

Product Classification

Regional Availability	Latin America North America
Portfolio	CommScope®
Product Type	Fiber patch/splice panel
Product Series	FL2000

General Specifications


Functionality	Patching Splicing
Adapter Packs Included, quantity	8
Cable Exit Location	Rear, left side Rear, right side
Color	Putty white
Color, front	Putty white
Growth Configuration	Fully loaded
Interface, front	FC/UPC
Patching Capacity, maximum	48
Rack Type	EIA 19 in
Rack Units	5
Shelf Movement	Hinged
Splicing Capacity, maximum	48
Total Ports, quantity	48

Dimensions

Height	222.25 mm 8.75 in
Width	482.6 mm 19 in
Depth	256.54 mm 10.1 in

FL2-C420048PW-4A00

Ordering Tree

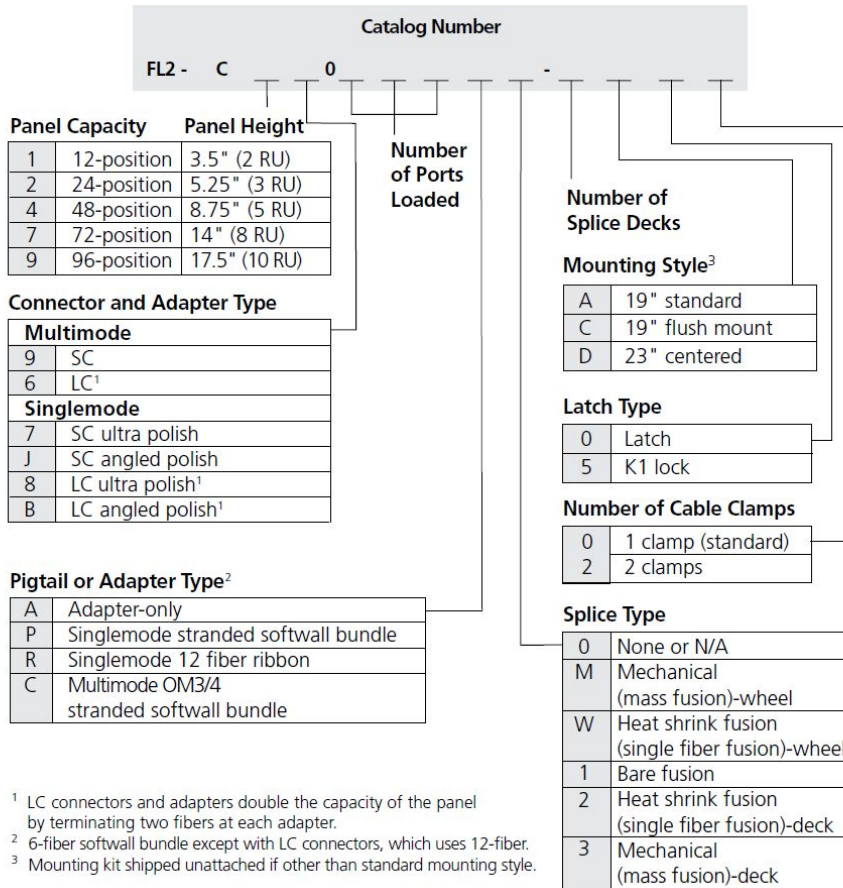

Material Specifications

Finish	Powder coated
Material Type	Steel

Optical Specifications

Fiber Mode	Singlemode
-------------------	------------

Environmental Specifications

Operating Temperature	-40 °C to +70 °C (-40 °F to +158 °F)
Storage Temperature	-40 °C to +85 °C (-40 °F to +185 °F)

Packaging and Weights

FL2-C420048PW-4A00

Included	Mounting hardware
Packaging quantity	1

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant/Exempted
UK-ROHS	Compliant

