

FL2-R180024A0-0A00

FL2000 Fiber Termination Panel, 24 LC/UPC, singlemode, 1RU, 19 in, putty white

Product Classification

Regional Availability	Latin America North America
Portfolio	CommScope®
Product Type	Fiber patch panel
Product Series	FL2000

General Specifications


Functionality	Patching
Adapter Packs Included, quantity	2
Color	Putty white
Growth Configuration	Fully loaded
Interface, front	LC/UPC
Rack Type	EIA 19 in
Rack Units	1
Shelf Movement	Hinged
Splicing Capacity, maximum	0
Total Ports, quantity	24

Dimensions

Height	44.45 mm 1.75 in
Width	482.6 mm 19 in
Depth	256.54 mm 10.1 in

Ordering Tree

FL2-R180024A0-0A00

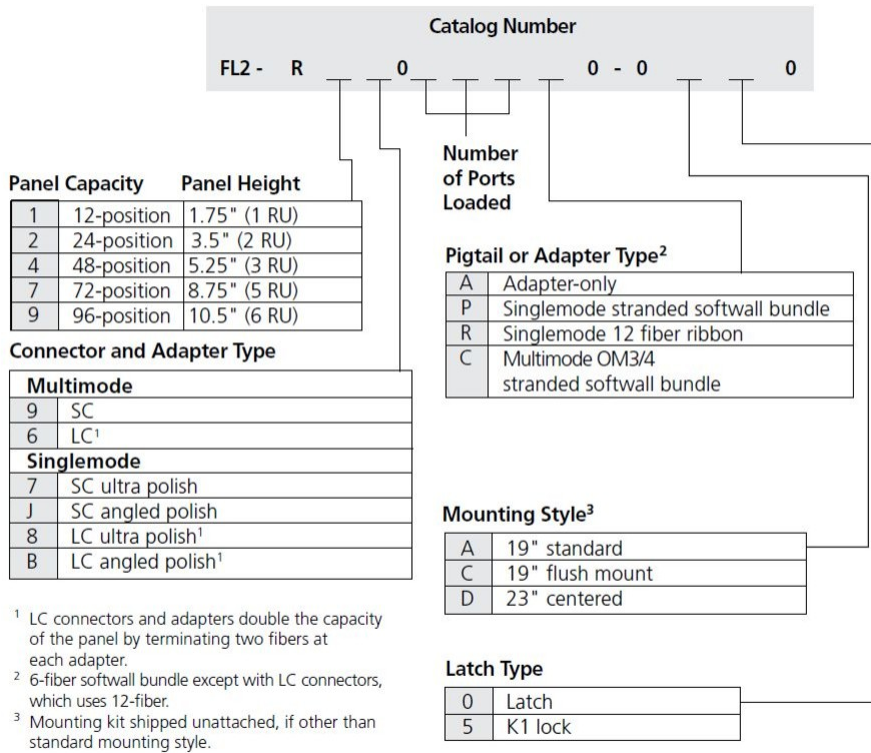

Material Specifications

Finish	Powder coated
Material Type	Steel

Optical Specifications

Fiber Mode	Singlemode
-------------------	------------

Environmental Specifications

Operating Temperature	-40 °C to +70 °C (-40 °F to +158 °F)
Storage Temperature	-40 °C to +85 °C (-40 °F to +185 °F)

Packaging and Weights

Included	Mounting hardware
Packaging quantity	1

Regulatory Compliance/Certifications

FL2-R180024A0-0A00

Agency**Classification**

CHINA-ROHS

Above maximum concentration value

ISO 9001:2015

Designed, manufactured and/or distributed under this quality management system

REACH-SVHC

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

ROHS

Compliant/Exempted

UK-ROHS

Compliant/Exempted

