

# FL2-S7B0AH016-DU00

---

FL2000 Fiber Termination Panel, 144 LC/APC, singlemode, 5RU, 23 in, putty white, pre-terminated with IFC cable, 16 meters, Stub tail at far end

## Product Classification

<b>Regional Availability</b>	Latin America   North America
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Fiber patch panel, with IFC cable
<b>Product Series</b>	FL2000

## General Specifications


<b>Functionality</b>	Patching
<b>Adapter Packs Included, quantity</b>	12
<b>Cable Exit Location</b>	Upward
<b>Cable Stub Type</b>	IFC
<b>Color</b>	Putty white
<b>Growth Configuration</b>	Fully loaded
<b>Interface, front</b>	LC/APC
<b>Interface, rear</b>	Stub tail
<b>Rack Type</b>	EIA 23 in
<b>Rack Units</b>	5
<b>Shelf Movement</b>	Hinged
<b>Splicing Capacity, maximum</b>	0
<b>Total Ports, quantity</b>	144

## Dimensions

<b>Height</b>	222.25 mm   8.75 in
<b>Width</b>	584.2 mm   23 in
<b>Depth</b>	256.54 mm   10.1 in
<b>Cable Length</b>	16 m   52.493 ft

## Ordering Tree

# FL2-S7B0AH016-DU00

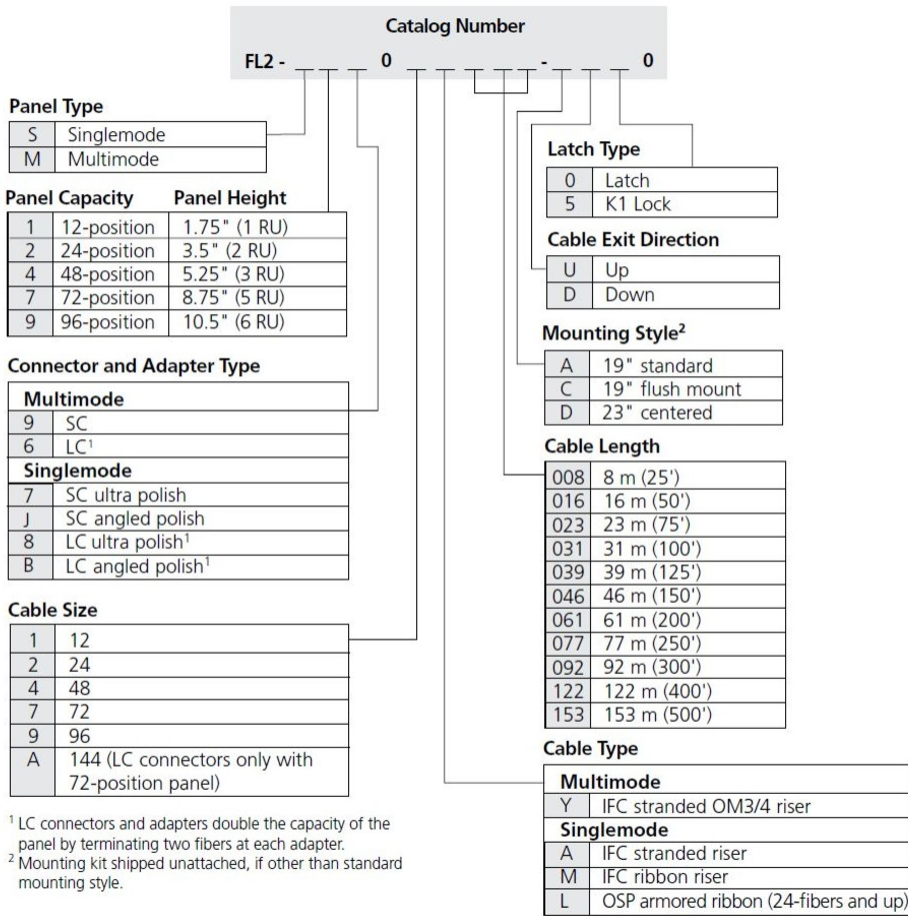

## Material Specifications

**Finish** Powder coated

**Material Type** Steel

## Optical Specifications

**Fiber Mode** Singlemode

## Environmental Specifications

**Operating Temperature** -40 °C to +70 °C (-40 °F to +158 °F)

**Storage Temperature** -40 °C to +85 °C (-40 °F to +185 °F)

## Packaging and Weights

**Packaging quantity** 1

# FL2-S7B0AH016-DU00

---

## Regulatory Compliance/Certifications

<b>Agency</b>	<b>Classification</b>
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted

