


SSC-760237600

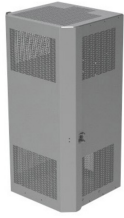

Middle of Pole Micro Concealment Enclosure for up Low, Mid, and High Power Samsung, Ericsson, and Nokia Radios

- Intended to be used with high powered remote radio heads on standard street lighting and wood pole structures where low-visual impact is desired
- Enables attractive concealment and securing of all site equipment on standard street lighting structures
- Highly-flexible configuration can house diplexers, AC load center, and/or fiber demarcation

SSC-760237600E1x Ericsson
SSC-760237600E2x Ericsson 4490/4890
SSC-760237600S1x Samsung
SSC-760237600N3x Nokia

Includes Standard Mounting kit for through bolt, clamp, and banding

Available After Market KIts, ordered separate:
-860649584S-xx 5" Standoff for wood poles
-860649584ST-xx Standoff for Round Tapered Poles

Product Classification

| | |
|----------------------|-------------------------------------|
| Product Type | Mid pole |
| Product Brand | Metro Cell |
| Ordering Note | ANDREW® standard product with terms |
| Warranty | One year |

General Specifications

| | |
|--------------------------------------|--|
| Antennas Included | None |
| Color | Light Gray (RAL 7035) |
| Color Options | Beige-Grey (RAL 7006) Black (RAL 9005) Black Green (RAL 6012) Brown (RAL 8014) Faux Concrete Green (RAL 6005) Metallic Silver Umbra Grey (RAL 7022) White (RAL 9010) |
| Cooling | Passive Cooling |
| Mounting Options | Non-tapered poles Tapered poles Wood poles |
| Power Supply Compatibility | CCI PSU-1200W-48-N DELTA 1.0 DELTA 2.0 PSU-AC-08 |
| Radio Compatibility, Ericsson | 220x 440x 4415 4426 4435 4449 4455 4490 4890 8843 Diplexer PSU-AC-08 Power Distribution |
| Radio Compatibility, Nokia | AHBCA AHFIA AHFIB AHFIC AHLBA CCI Diplexer Power Distribution |
| Radio Compatibility Samsung | Diplexer Power Distribution RF4402D-D1A RFV01U-D1A RT2201-46A RT4401-48A |
| Radios Included | None |

SSC-760237600

Dimensions

| | |
|---------------|--------------------|
| Height | 1,117.6 mm 44 in |
| Width | 533.4 mm 21 in |
| Depth | 508 mm 20 in |

Electrical Specifications

| | |
|--------------------------|-----------------------------------|
| Power/Fiber Input | Trade size knockouts at rear side |
|--------------------------|-----------------------------------|

Material Specifications

| | |
|----------------------------------|------------------|
| Finish Aluminum | Chromate |
| Finish Concealment Covers | Powder coated |
| Material Type | Aluminum Steel |

Environmental Specifications

| | |
|---------------------------|--------|
| Thermal Compliance | GR-487 |
|---------------------------|--------|

Packaging and Weights

| | |
|--------------------------|---|
| Volume | 0.303 m ³ 10.7 ft ³ |
| Weight (loaded) | 136.078 kg 300 lb |
| Weight (unloaded) | 49.895 kg 110 lb |