



Fiber Optic Patch Cord, Duplex, OM3, LC/UPC to LC/UPC, LSZH, Aqua

Product Classification

Regional Availability	Asia   Australia/New Zealand   China   India
Portfolio	CommScope®
Product Type	Fiber patch cord, duplex
Product Series	192


General Specifications

Connector A, quantity	2
Color, boot A	Blue
Color, connector A	Beige
Connector B, quantity	2
Color, boot B	Blue
Color, connector B	Beige
Interface, Connector A	LC/UPC
Interface, Connector B	LC/UPC
Jacket Color	Aqua
Polarity	Pairs, flipped
Total Fibers, quantity	2

Dimensions

Cable Assembly Length Range (m)	1 – 100
Diameter Over Jacket	1.8 mm   0.071 in

Ordering Tree

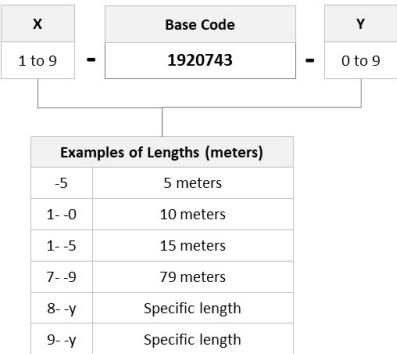

Mechanical Specifications

Cable Retention Strength, maximum11.24 lb @ 0 °

Optical Specifications

Fiber ModeMultimode  
Fiber TypeOM3, LazrSPEED®  
Insertion Loss, maximum0.15 dB  
Return Loss, minimum35 dB

Environmental Specifications

Operating Temperature-10 °C to +60 °C (+14 °F to +140 °F)  
Environmental SpaceLow Smoke Zero Halogen (LSZH)  
Qualification StandardsIEC 60332-1 | IEC 60332-3 | IEC 60754 | IEC 61034

Packaging and Weights

Packaging quantity1

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system

REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant
UK-ROHS	Compliant

