


F4ZMPSCAD

Base Product

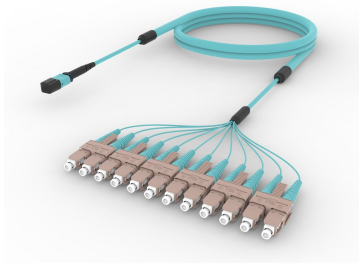

OM3 MPO (Unpinned) to SC/UPC, InstaPATCH® 360 Ruggedized Fanout Cable, 12-Fiber, Low Smoke Zero Halogen B2ca

OBSOLETE

This product was discontinued on: October 7, 2024

Product Classification

| | |
|------------------------------|-------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| Regional Availability | Europe |
| Portfolio | CommScope® |
| Product Type | Ruggedized fanout |
| Product Brand | SYSTIMAX InstaPATCH® 360 |
| Ordering Note | For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration Not available in the United States or Canada |

General Specifications

| | |
|-------------------------------------|-------------------|
| Color, boot A | Black |
| Color, connector A | Aqua |
| Color, boot B | Aqua |
| Color, connector B | Black |
| Construction Type | Stranded |
| Furcation Color | Aqua |
| Interface, Connector A | MPO-12/UPC Female |
| Interface, Connector B | SC/UPC |
| Jacket Color | Aqua |
| Polarity | Method B (LL) |
| Fibers per Subunit, quantity | 12 |

F4ZMPSCAD


Total Fibers, quantity 12

Dimensions

Cable Assembly Length Range (m) 3 – 999

Cable Assembly Length Range (ft) 7 – 999

Ordering Tree

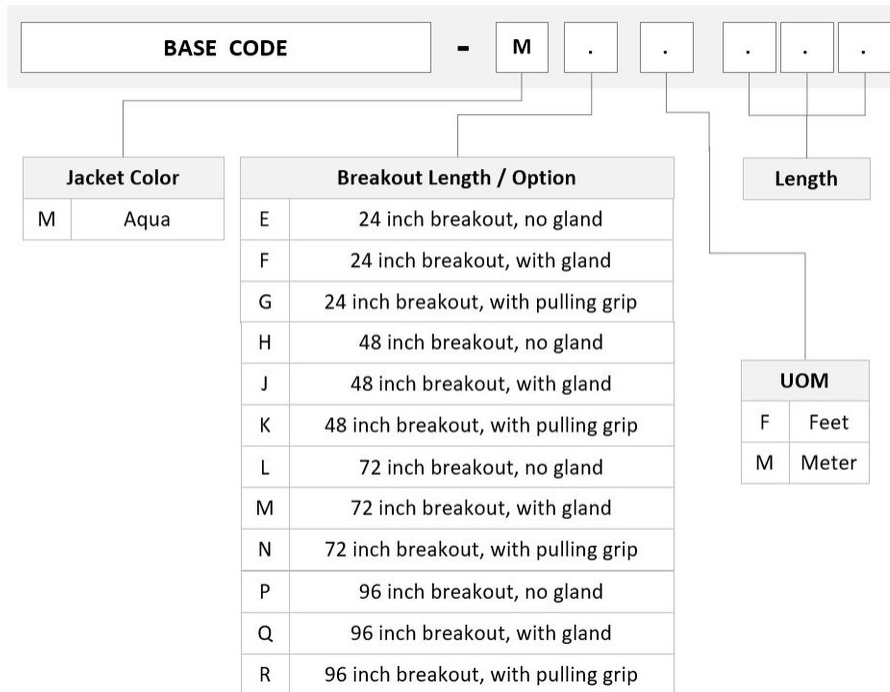

Mechanical Specifications

Cable Retention Strength, maximum 11.24 lb @ 0° | 4.40 lb @ 90°

Optical Specifications

Fiber Mode Multimode

Fiber Type OM3, LazrSPEED®

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)

EN50575 CPR Cable EuroClass Fire Performance B2ca

F4ZMPSCAD

Environmental Space

Indoor | Low Smoke Zero Halogen (LSZH)

Regulatory Compliance/Certifications

| Agency | Classification |
|---------------|--------------------------------------------------------------------------------------------------------------------------------|
| ANATEL | Compliant |
| CHINA-ROHS | Below maximum concentration value |
| ISO 9001:2015 | Designed, manufactured and/or distributed under this quality management system |
| REACH-SVHC | Compliant as per SVHC revision on www.commscope.com/ProductCompliance |
| ROHS | Compliant |
| UK-ROHS | Compliant |



Included Products

| | | |
|----------------------|---|---------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| 460125750 | - | LazrSPEED® Pre-Radiused SC Connector for 1.6 mm Fiber Cordage, Duplex, multimode |
| 760239592 | - | Fiber Indoor Cable, LazrSPEED® Low Smoke Zero Halogen Riser MPO Trunk Cable, 12 fiber, Gel-free, Multimode OM3, B2ca Flame Rating, Feet jacket marking, Aqua jacket color |
| N-012-MP-5L-F12AQ/B2 | - | |
| 860647054 | - | MPO12, LOW LOSS, FEMALE, OM3/4, AQUA, 3mm |