


# FJVMPPAL

## Base Product

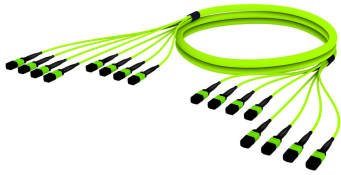

OM5 MPO (Unpinned) to MPO (Unpinned), InstaPATCH® 360 Pre-terminated Trunk Cable, 96-Fiber, Low Smoke Zero Halogen

- LazrSPEED® WideBand extends the capability of OM4 across enough spectrum to support at least four low-cost wavelengths

## Product Classification

### Regional Availability

Asia | Australia/New Zealand | China | Europe | India | Latin America | Middle East/Africa | North America

### Portfolio

CommScope®

### Product Type

Fiber trunk cable assembly

### Product Brand

SYSTIMAX InstaPATCH® 360

### Ordering Note

For additional jacket colors, please contact a CommScope Sales Representative | For lengths greater than 999 ft (304 m), orders must be in meters | Minimum length may vary based on cable configuration

## General Specifications

### Color, boot A

Black

### Color, connector A

Lime green

### Color, boot B

Black

### Color, connector B

Lime green

### Construction Type

Stranded

### Furcation Color

Lime green

### Interface, Connector A

MPO-12/UPC Female

### Interface, Connector B

MPO-12/UPC Female

### Jacket Color

Lime green

### Polarity

Method B (LL)

### Fibers per Subunit, quantity

12

### Total Fibers, quantity

96

## Dimensions

### Breakout Length

33 in

### Cable Assembly Length Range (m)


3 – 999

# FJVMPPAL

Cable Assembly Length Range (ft)

10 – 999

## Ordering Tree

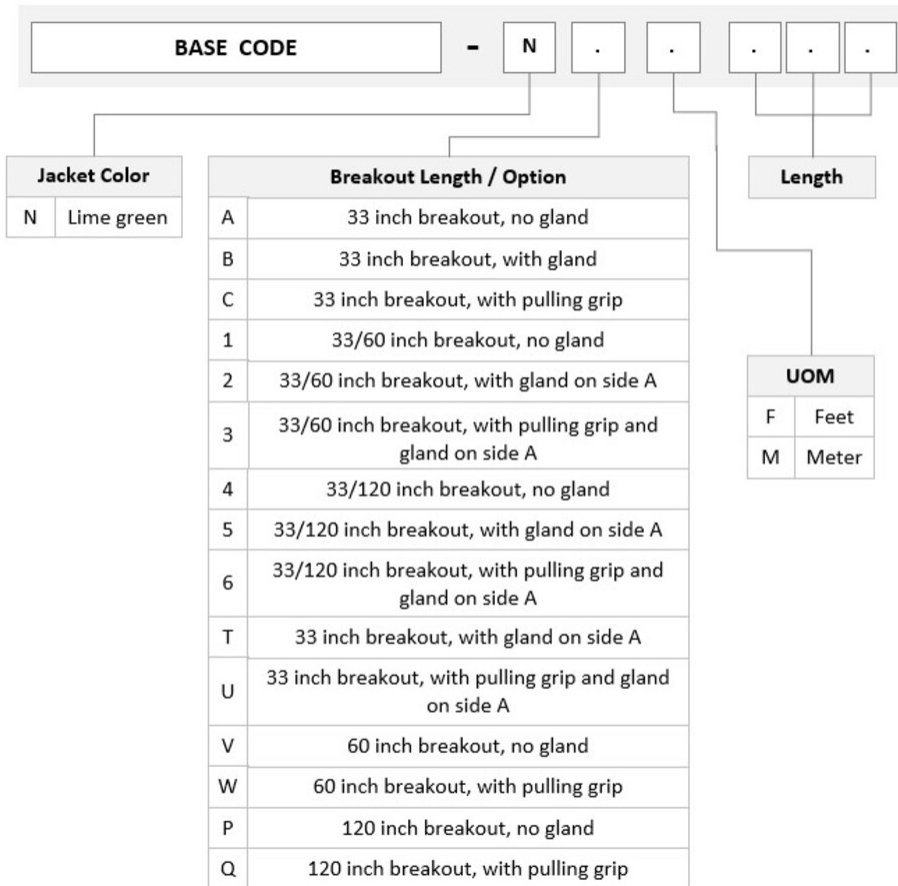

## Mechanical Specifications

**Cable Retention Strength, maximum** 11.24 lb @ 0° | 4.40 lb @ 90°

## Optical Specifications

**Fiber Mode** Multimode

**Fiber Type** OM5, LazrSPEED®

## Environmental Specifications

**Operating Temperature** -10 °C to +60 °C (+14 °F to +140 °F)

# FJVMPPAL

Environmental Space

Dual Rated LSZH/Riser | Indoor

## Regulatory Compliance/Certifications

| Agency        | Classification   |
|---------------|--|
| ANATEL        | Compliant  |
| CHINA-ROHS    | Above maximum concentration value  |
| ISO 9001:2015 | Designed, manufactured and/or distributed under this quality management system   |
| REACH-SVHC    | Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a> |
| ROHS          | Compliant/Exempted   |
| UK-ROHS       | Compliant/Exempted   |



## Included Products

- |                                  |   |  |
|----------------------------------|---|--|
| 760229096<br>N-096-MP-5G-F12LM/D | - | Fiber indoor cable, LazrSPEED® Low Smoke Zero Halogen Riser MPO Trunk, 96 fiber multi-unit with 12 fiber subunits, Gel-free, Multimode OM5, Feet jacket marking, Lime green jacket color, Dca flame rating |
| 860647056                        | - | MPO12, LOW LOSS, FEMALE, OM5, LIME, 3mm  |