

# FKXMPMPAL

## Base Product



OM4 MPO (Unpinned) to MPO (Unpinned), InstaPATCH® 360 Armored Pre-terminated Trunk Cable, 96-Fiber, Low Smoke Zero Halogen

### OBSOLETE

This product was discontinued on: October 7, 2024

#### Replaced By:

UKXMPMPCL

Ultra Low Loss (ULL) OM4 MPO12 UPC (unpinned) to MPO12 UPC (unpinned) Fiber Trunk Cable Assembly, 96-Fiber, Armored Indoor Low Smoke Zero Halogen (LSZH)

## Product Classification

### Regional Availability

Asia | Australia/New Zealand | China | India | Latin America | Middle East /Africa | North America

### Portfolio

CommScope®

### Product Type

Fiber trunk cable assembly

### Product Brand

SYSTIMAX InstaPATCH® 360

### Ordering Note

For lengths greater than 999 ft (304 m), orders must be in meters | Minimum length may vary based on cable configuration | Not available in the United States or Canada

## General Specifications

<b>Color, boot A</b>	Black
<b>Color, connector A</b>	Aqua
<b>Color, boot B</b>	Black
<b>Color, connector B</b>	Aqua
<b>Construction Type</b>	Armored   Stranded
<b>Furcation Color</b>	Aqua
<b>Interface, Connector A</b>	MPO-12/UPC Female
<b>Interface, Connector B</b>	MPO-12/UPC Female
<b>Jacket Color</b>	Aqua
<b>Polarity</b>	Method B (LL)
<b>Fibers per Subunit, quantity</b>	12

# FKXMPMPAL

**Total Fibers, quantity** 96


## Dimensions

**Breakout Length** 33 in

**Cable Assembly Length Range (m)** 3 – 999

**Cable Assembly Length Range (ft)** 10 – 999

## Ordering Tree

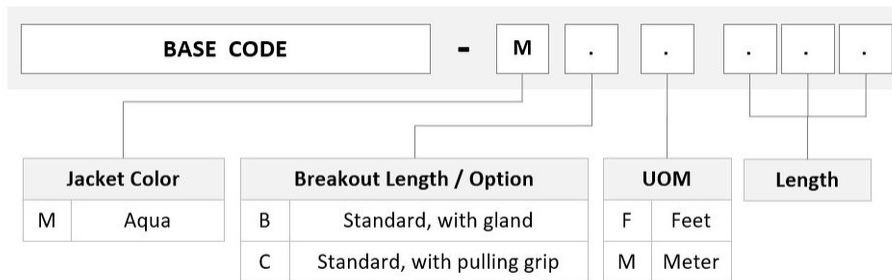

## Mechanical Specifications

**Cable Retention Strength, maximum** 11.24 lb @ 0 ° | 4.40 lb @ 90 °

## Optical Specifications

**Fiber Mode** Multimode

**Fiber Type** OM4, LazrSPEED®

## Environmental Specifications

**Operating Temperature** -10 °C to +60 °C (+14 °F to +140 °F)

**Environmental Space** Dual Rated LSZH/Riser | Indoor

## Regulatory Compliance/Certifications

Agency	Classification
ANATEL	Compliant
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant/Exempted

# FKXMPMPAL

---

UK-ROHS

Compliant/Exempted



## Included Products

- |                                |   |  |
|--------------------------------|---|--|
| 760120097<br>N-096-MZ-5K-F12AQ | - | Fiber indoor cable, LazrSPEED® Riser/LSZH rated, MPO Trunk, interlocking aluminum armored, Multimode OM4, 96 fiber multi-unit with 12 fiber subunits, Gel-free, Feet jacket marking, Aqua jacket color |
| 860647054                      | - | MPO12, LOW LOSS, FEMALE, OM3/4, AQUA, 3mm  |