


FLWLUCUCAG

Base Product

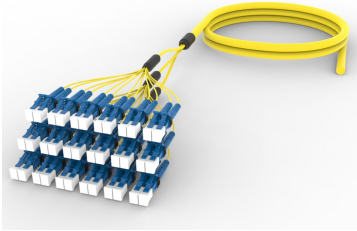

Singlemode LC/UPC to Unconnectorized 36-Fiber InstaPATCH® 360 Ruggedized Fanout Cable, Plenum

Product Classification

Regional Availability

Asia | Australia/New Zealand | China | Europe | India | Latin America | Middle East/Africa | North America

Portfolio

CommScope®

Product Type

Ruggedized fanout

Product Brand

SYSTIMAX InstaPATCH® 360

Ordering Note

For lengths greater than 999 ft (304 m), orders must be in meters | Minimum length may vary based on cable configuration

General Specifications

Color, boot A

Blue

Color, connector A

Blue

Construction Type

Stranded

Furcation Color

Yellow

Interface, Connector A

LC/UPC

Interface, Connector B

Unterminated

Jacket Color

Yellow

Fibers per Subunit, quantity

12

Total Fibers, quantity

36

Dimensions

Cable Assembly Length Range (m)

3 – 305

Cable Assembly Length Range (ft)

8 – 999

Ordering Tree

FLWLCUCAG



Included Products

- 760093484
P-036-MP-8W-F12YL
 - 860637435
- Fiber indoor cable, TeraSPEED® Plenum MPO Trunk, 36 fiber multi-unit with 12 fiber subunits, Singlemode G.652.D and G.657.A1, Gel-free, Feet jacket marking, Yellow jacket color
 - LC/UPC Connector, Singlemode, Blue, Short Boot