


# FLWSASAAK

## Base Product

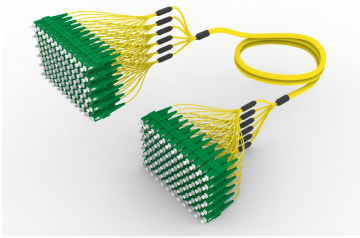

SingleMode SC/APC to SC/APC, InstaPATCH® 360 Ruggedized Fiber Fanout Cable Assembly, 72-Fiber, Plenum

## Product Classification

|                              |  |
|------------------------------|--|
| <b>Regional Availability</b> | Asia   Australia/New Zealand   China   Europe   India   Latin America   Middle East/Africa   North America               |
| <b>Portfolio</b>             | CommScope®   |
| <b>Product Type</b>          | Ruggedized fanout  |
| <b>Product Brand</b>         | SYSTIMAX InstaPATCH® 360   |
| <b>Ordering Note</b>         | For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration |

## General Specifications


|                                     |          |
|-------------------------------------|----------|
| <b>Color, boot A</b>                | Green    |
| <b>Color, connector A</b>           | Green    |
| <b>Color, boot B</b>                | Green    |
| <b>Color, connector B</b>           | Green    |
| <b>Construction Type</b>            | Stranded |
| <b>Furcation Color</b>              | Yellow   |
| <b>Interface, Connector A</b>       | SC/APC   |
| <b>Interface, Connector B</b>       | SC/APC   |
| <b>Jacket Color</b>                 | Yellow   |
| <b>Fibers per Subunit, quantity</b> | 12       |
| <b>Total Fibers, quantity</b>       | 72       |

## Dimensions

|   |         |
|---|---------|
| <b>Cable Assembly Length Range (m)</b>  | 3 – 305 |
| <b>Cable Assembly Length Range (ft)</b> | 8 – 999 |

# FLWSASAAK

## Ordering Tree

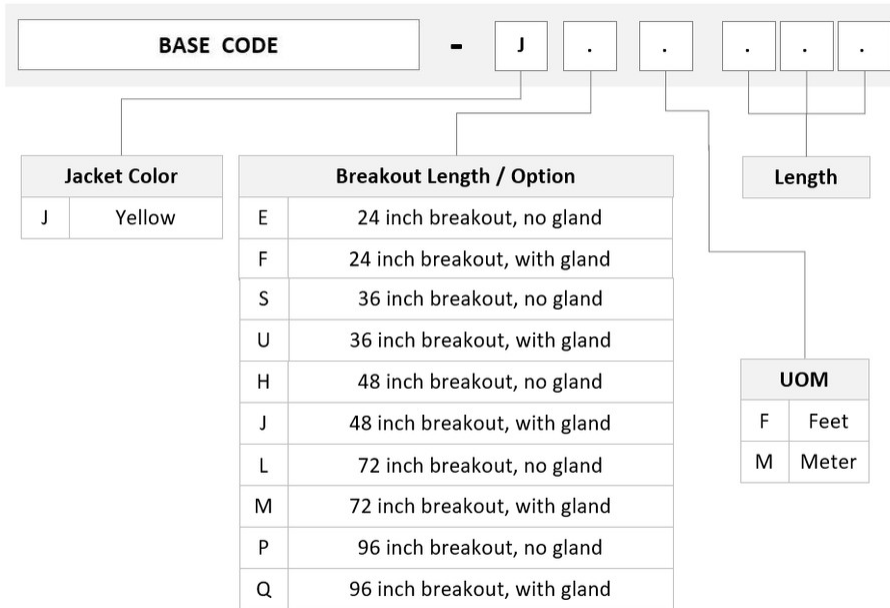

## Mechanical Specifications

**Cable Retention Strength, maximum** 11.24 lb @ 0 ° | 4.40 lb @ 90 °

## Optical Specifications

**Fiber Mode** Singlemode

**Fiber Type** G.652.D | G.657.A1, TeraSPEED®

## Environmental Specifications

**Operating Temperature** -10 °C to +60 °C (+14 °F to +140 °F)

**Environmental Space** Indoor | Plenum

## Regulatory Compliance/Certifications

### Agency

ANATEL

ISO 9001:2015

### Classification

Compliant

Designed, manufactured and/or distributed under this quality management system

# FLWSASAAK

---



## Included Products

- 460125784 – TeraSPEED® SC APC Connector for 1.6 mm Fiber, Duplex, Singlemode, green
- 760038331 – Fiber indoor cable, TeraSPEED® Plenum MPO Trunk, 72 fiber multi-unit with 12 fiber subunits, Singlemode G.652.D and G.657.A1, Gel-free, Feet jacket marking, Yellow jacket color
- P-072-MP-8W-F12YL