


FLXMPLCAL

Base Product

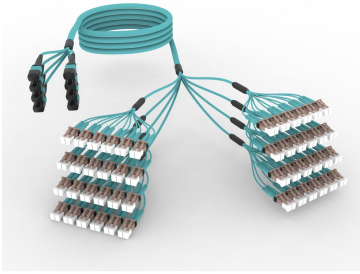

OM4 MPO (Unpinned) to LC/UPC, InstaPATCH® 360 Ruggedized Fanout Cable, 96-Fiber, Plenum

Product Classification

Regional Availability

Asia | Australia/New Zealand | China | Europe | India | Latin America | Middle East/Africa | North America

Portfolio

CommScope®

Product Type

Ruggedized fanout

Product Brand

SYSTIMAX InstaPATCH® 360

Ordering Note

For lengths greater than 999 ft (304 m), orders must be in meters | Minimum length may vary based on cable configuration

General Specifications

Color, boot A

Black

Color, connector A

Aqua

Color, boot B

Aqua

Color, connector B

Black

Construction Type

Stranded

Furcation Color

Aqua

Interface, Connector A

MPO-12/UPC Female

Interface, Connector B

LC/UPC

Jacket Color

Aqua

Polarity

Method B (LL)

Fibers per Subunit, quantity

12

Total Fibers, quantity

96

Dimensions

Cable Assembly Length Range (m)

3 – 999

FLXMPLCAL

Cable Assembly Length Range (ft)

7 – 999

Ordering Tree



Mechanical Specifications

Cable Retention Strength, maximum 11.24 lb @ 0 ° | 4.40 lb @ 90 °

Optical Specifications

Fiber Mode Multimode

Fiber Type OM4, LazrSPEED®

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)

Environmental Space Indoor | Plenum

Regulatory Compliance/Certifications

FLXMPLCAL

Agency	Classification
ANATEL	Compliant
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant



Included Products

760051664	-	Fiber indoor cable, LazrSPEED® Plenum MPO Trunk, 96 fiber multi-unit with 12 fiber subunits, Multimode OM4, Gel-free, Feet jacket marking, Aqua jacket color
P-096-MP-5K-F12AQ	-	
860637378	-	LazrSPEED® Elite LC Connector duplex for 1.6 mm Fiber, multimode
860647054	-	MPO12, LOW LOSS, FEMALE, OM3/4, AQUA, 3mm