


# FSXLCLCWK

## Base Product

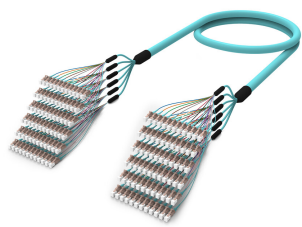

LazrSPEED® 550 LC/UPC to LC/UPC, Distribution Cable, 72-Fiber, Plenum

## Product Classification

Regional Availability	North America
Portfolio	CommScope®
Product Type	Fiber distribution cable assembly
Product Brand	SYSTIMAX InstaPATCH® 360
Ordering Note	For lengths greater than 999 ft (304 m), orders must be in meters

## General Specifications


Cable Glands	No glands
Color, connector A	Beige
Color, connector B	Beige
Construction Type	Distribution, indoor
Interface, Connector A	LC/UPC
Interface, Connector B	LC/UPC
Total Fibers, quantity	72

## Dimensions

Cable Assembly Length Range (m)	3 – 305
Cable Assembly Length Range (ft)	7 – 999

## Ordering Tree

# FSXLCLCWK

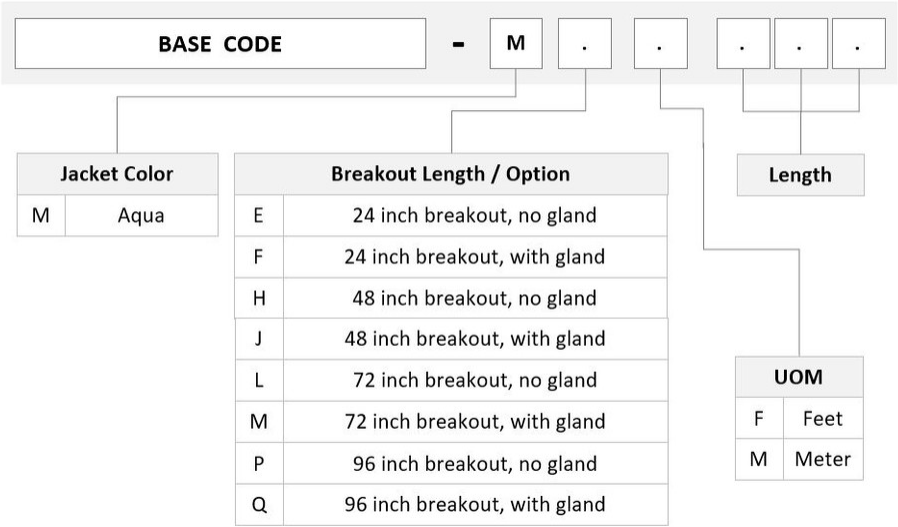

## Mechanical Specifications

**Cable Retention Strength, maximum** 0.50 lb @ 0 ° | 0.50 lb @ 90 °

## Optical Specifications

**Fiber Mode** Multimode  
**Fiber Type** OM4, LazrSPEED®

## Environmental Specifications

**Operating Temperature** 0 °C to +70 °C (+32 °F to +158 °F)  
**Environmental Space** Plenum

## Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant
UK-ROHS	Compliant



# FSXLCLCWK

---

## Included Products

- |                 |   |  |
|-----------------|---|--|
| 460125271       | – | Behind The Wall Pre-Radiused LC Connector for 0.9 mm Fiber, multimode  |
| P-072-DS-5K-FMU | – | Fiber indoor cable, LazrSPEED® Plenum Distribution, 72-Fiber Multi-Unit with 12-Fiber Subunits, Multimode OM4, Gel-free, Feet jacket marking |