


U4GLFLFCL

Base Product

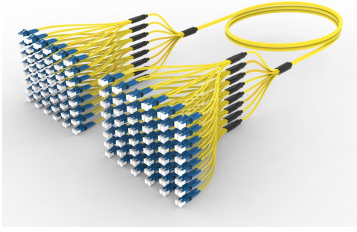

Ultra Low Loss ULL TeraSPEED® LC/UPC G B to LC/UPC G B
Ruggedized fanout Cable, 96-Fiber, LSZH, 12 fiber PmP 2.0 mm /B2ca

Product Classification

Regional Availability	Asia Australia/New Zealand Europe Latin America Middle East/Africa North America
Portfolio	CommScope®
Product Type	Ruggedized fanout
Product Brand	SYSTIMAX ULL
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration

General Specifications

Color, boot A	Blue
Color, connector A	Green
Color, boot B	Blue
Color, connector B	Blue
Construction Type	Stranded
Furcation Color	Yellow
Interface, Connector A	LC/UPC
Interface Feature, connector A	Grade B performance
Interface, Connector B	LC/UPC
Interface Feature, connector B	Grade B performance
Jacket Color	Yellow
Fibers per Subunit, quantity	12
Total Fibers, quantity	96

Dimensions


Cable Assembly Length Range (m)	3 – 305
--	---------

U4GLFLFCL

Cable Assembly Length Range (ft)

10 – 999

Ordering Tree

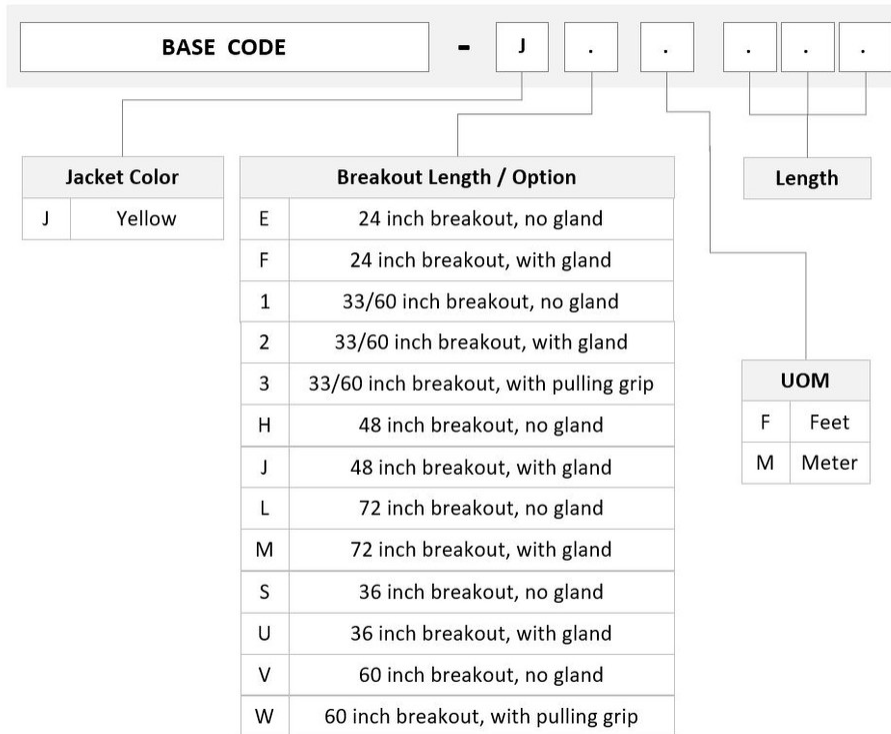

Optical Specifications

Fiber Mode

Singlemode

Fiber Type

G.657.A2, TeraSPEED®

Environmental Specifications

Operating Temperature

-10 °C to +60 °C (+14 °F to +140 °F)

EN50575 CPR Cable EuroClass Fire Performance

B2ca

Environmental Space

Indoor | Low Smoke Zero Halogen (LSZH)

Regulatory Compliance/Certifications

Agency

Classification

ANATEL

Compliant

CHINA-ROHS

Below maximum concentration value

U4GLFLFCL

ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant

