


# U4GSCSCCH

## Base Product

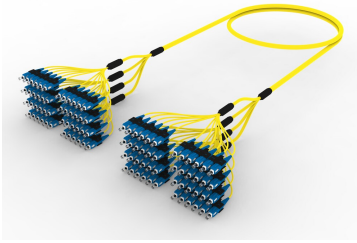

Ultra Low Loss ULL TeraSPEED® SC/UPC to SC/UPC Ruggedized fanout Cable, 48-Fiber, LSZH, 12 fiber PmP 2.0 mm /B2ca

## Product Classification

### Regional Availability

Asia | Australia/New Zealand | Europe | Latin America | Middle East/Africa | North America

### Portfolio

CommScope®

### Product Type

Ruggedized fanout

### Product Brand

SYSTIMAX ULL

### Ordering Note

For additional jacket colors, please contact a CommScope Sales Representative | For lengths greater than 999 ft (304 m), orders must be in meters | Minimum length may vary based on cable configuration

## General Specifications

### Color, boot A

Blue

### Color, connector A

Green

### Color, boot B

Blue

### Color, connector B

Blue

### Construction Type

Stranded

### Furcation Color

Yellow

### Interface, Connector A

SC/UPC

### Interface Feature, connector A

ULL

### Interface, Connector B

SC/UPC

### Interface Feature, connector B

ULL

### Jacket Color

Yellow

### Fibers per Subunit, quantity

12

### Total Fibers, quantity

48

## Dimensions

### Cable Assembly Length Range (m)

3 – 305

# U4GSCSCCH

Cable Assembly Length Range (ft)

10 – 999

## Ordering Tree



## Optical Specifications

**Fiber Mode**

Singlemode

**Fiber Type**

G.657.A2, TeraSPEED®

## Environmental Specifications

**Operating Temperature**

-10 °C to +60 °C (+14 °F to +140 °F)

**EN50575 CPR Cable EuroClass Fire Performance**

B2ca

**Environmental Space**

Indoor | Low Smoke Zero Halogen (LSZH)

## Regulatory Compliance/Certifications

**Agency**

**Classification**

ANATEL

Compliant

# U4GSCSCCH

---

ISO 9001:2015

Designed, manufactured and/or distributed under this quality management system

