


U4VMPLCAD

Base Product

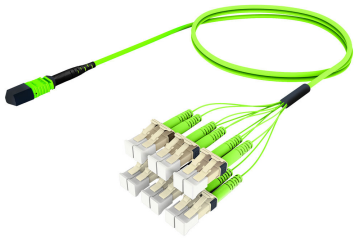

Ultra Low Loss (ULL) OM5 MPO (Unpinned) to LC/UPC, InstaPATCH® 360 Ruggedized Fanout Cable Assembly, 12-Fiber, Low Smoke Zero Halogen (LSZH)

This product will be discontinued on: April 30, 2024

Replaced By:

U4VMPLCCD

Ultra Low Loss ULL LazrSPEED® 550 OM5 MPO(Unpinned) to LC/UPC Ruggedized fanout Cable, 12-Fiber, LSZH, 12 fiber PmP 2.0 mm /B2ca

Product Classification

| | |
|------------------------------|---|
| Regional Availability | Europe |
| Portfolio | CommScope® |
| Product Type | Ruggedized fanout |
| Product Brand | SYSTIMAX InstaPATCH® 360 SYSTIMAX ULL |
| Ordering Note | For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration Not available in the United States or Canada |

General Specifications

| | |
|-------------------------------|-------------------------|
| Color, boot A | Black |
| Color, connector A | Lime green |
| Color, boot B | Lime green |
| Color, connector B | Beige |
| Construction Type | Stranded |
| Furcation Color | Lime green |
| Interface, Connector A | MPO-12/UPC Female |
| Interface, Connector B | LC/UPC |
| Jacket Color | Lime green |
| Polarity | Method B Enhanced (ULL) |

U4VMPLCAD

Fibers per Subunit, quantity 12


Total Fibers, quantity 12

Dimensions

Cable Assembly Length Range (m) 3 – 999

Cable Assembly Length Range (ft) 7 – 999

Ordering Tree

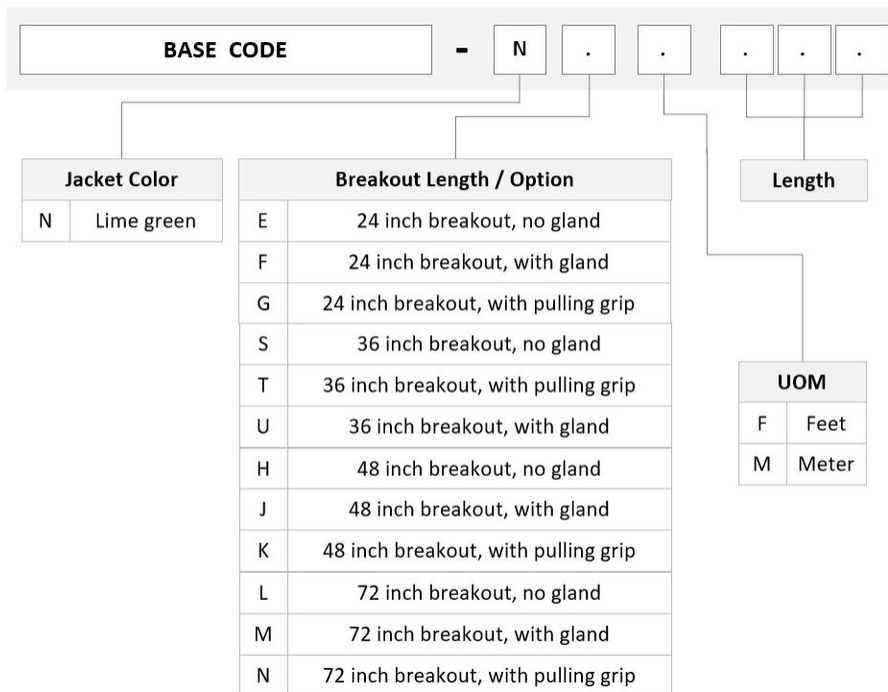

Optical Specifications

Fiber Mode Multimode

Fiber Type OM5, LazrSPEED®

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)

Environmental Space Indoor | Low Smoke Zero Halogen (LSZH)

Regulatory Compliance/Certifications

U4VMPLCAD

| Agency | Classification |
|---------------|--|
| ANATEL | Compliant |
| CHINA-ROHS | Below maximum concentration value |
| ISO 9001:2015 | Designed, manufactured and/or distributed under this quality management system |
| REACH-SVHC | Compliant as per SVHC revision on www.commscope.com/ProductCompliance |
| ROHS | Compliant |
| UK-ROHS | Compliant |



Included Products

| | |
|-----------------------------------|---|
| 760239605 N-012-MP-5G-F12LM/B2 | - Fiber Indoor Cable, LazrSPEED® Low Smoke Zero Halogen Riser MPO Trunk Cable, 12 fiber, Gel-free, Multimode OM5, B2ca Flame Rating, Feet jacket marking, Lime green jacket color |
| 860617232 | - MPO12, ULTRA LOW LOSS, FEMALE, OM5, LIME, 3mm |
| 860637378 | - LazrSPEED® Elite LC Connector duplex for 1.6 mm Fiber, multimode |
| CS-5G-MP | - LazrSPEED® OM5 WideBand Multimode Fiber |