

UDVLCUC42



Ultra Low Loss (ULL) OM5 LC/UPC to Unconnectorized, 1.6 mm Duplex Fiber Pigtail, Plenum

Product Classification

| | |
|------------------------------|--|
| Regional Availability | Asia Australia/New Zealand Europe Latin America Middle East /Africa North America |
| Portfolio | CommScope® |
| Product Type | Fiber pigtail, jacketed |
| Product Brand | SYSTEMAX ULL |
| Ordering Note | For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration |

General Specifications


| | |
|-------------------------------|------------|
| Color, boot A | Lime green |
| Color, connector A | Beige |
| Interface, Connector A | LC/UPC |
| Jacket Color | Lime green |
| Total Fibers, quantity | 2 |

Dimensions

| | |
|---|-------------------|
| Cable Assembly Length Range (m) | 1 – 61 |
| Cable Assembly Length Range (ft) | 2 – 200 |
| Diameter Over Jacket | 1.6 mm 0.063 in |

Ordering Tree

UDVLCUC42

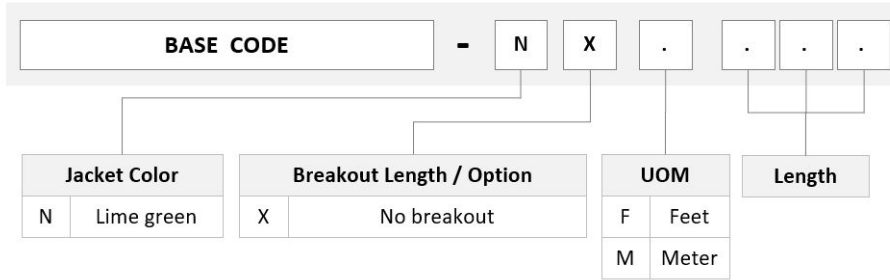

Mechanical Specifications

Cable Retention Strength, maximum 11.24 lb @ 0 ° | 4.40 lb @ 90 °

Optical Specifications

Fiber Mode Multimode

Fiber Type OM5, LazrSPEED®

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)

Environmental Space Plenum

Regulatory Compliance/Certifications

Agency

ANATEL

ISO 9001:2015

Classification

Compliant

Designed, manufactured and/or distributed under this quality management system



Included Products

- 760233361 P-002-ZC-5G-F16LM – Fiber indoor cable, LazrSPEED® 1.6 mm Plenum Zipcord, Multimode OM5, Feet jacket marking, Lime green jacket color
- 860637378 – LazrSPEED® Elite LC Connector duplex for 1.6 mm Fiber, multimode