

UFVLCUC21



Ultra Low Loss (ULL) OM5 LC/UPC to Unconnectorized, 1.6 mm Simplex Fiber Pigtail, Low Smoke Zero Halogen (LSZH)

Product Classification

Regional Availability	Asia Australia/New Zealand Europe Latin America Middle East /Africa North America
Portfolio	CommScope®
Product Type	Fiber pigtail, jacketed
Product Brand	SYSTIMAX ULL
Ordering Note	For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration


General Specifications

Color, boot A	Lime green
Color, connector A	Beige
Interface, Connector A	LC/UPC
Jacket Color	Lime green
Total Fibers, quantity	1

Dimensions

Cable Assembly Length Range (m)	1 – 61
Cable Assembly Length Range (ft)	2 – 200
Diameter Over Jacket	1.6 mm 0.063 in

Ordering Tree

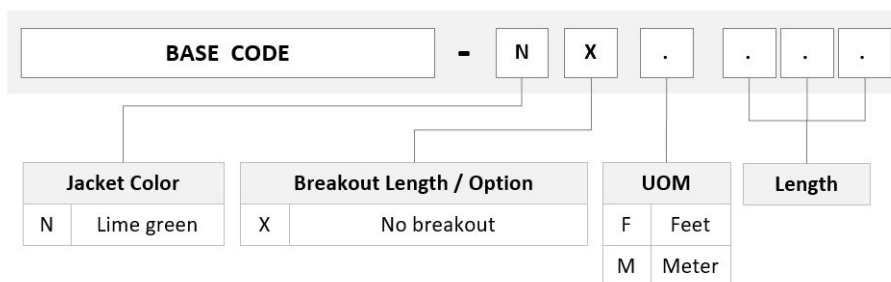

UFVLCUC21

Mechanical Specifications

Cable Retention Strength, maximum 11.24 lb @ 0° | 4.40 lb @ 90°

Optical Specifications

Fiber Mode Multimode

Fiber Type OM5, LazrSPEED®

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)

Environmental Space Dual Rated LSZH/Riser

Regulatory Compliance/Certifications

Agency	Classification
ANATEL	Compliant
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted



Included Products

- 760238502 N-001-SP-5G-F16LM/E – Fiber Indoor Cable, LazrSPEED® 1.6mm Low Smoke Zero Halogen Riser, 1-fiber Simplex, Multimode OM5, Feet jacket marking, Lime green jacket color, Eca Flame Rating
- 860637378 – LazrSPEED® Elite LC Connector duplex for 1.6 mm Fiber, multimode