

UFVLCUC42



Ultra Low Loss (ULL) LazrSPEED® 550 WideBand OM5 LC/UPC to Unconnectorized, Fiber Pigtail, 1.6 mm Duplex, LSZH

Product Classification

Regional Availability	Asia Australia/New Zealand Europe Latin America Middle East /Africa North America
Portfolio	CommScope®
Product Type	Fiber pigtail, jacketed
Product Brand	SYSTIMAX ULL
Ordering Note	For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration


General Specifications

Color, connector A	Beige
Interface, Connector A	LC/UPC
Jacket Color	Lime green
Total Fibers, quantity	2

Dimensions

Cable Assembly Length Range (m)	1 – 61
Cable Assembly Length Range (ft)	2 – 200
Diameter Over Jacket	1.6 mm 0.063 in

Ordering Tree

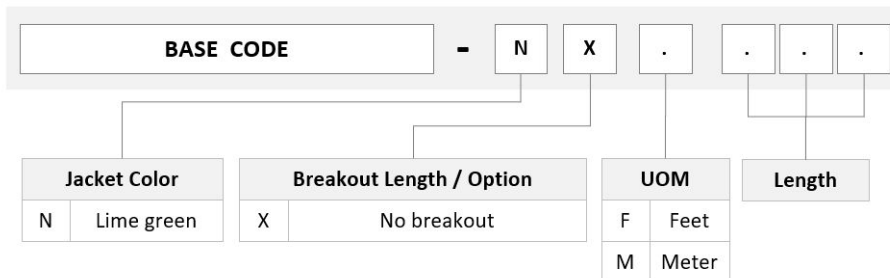

UFVLCUC42

Mechanical Specifications

Cable Retention Strength, maximum 11.24 lb @ 0 ° | 4.40 lb @ 90 °

Optical Specifications

Fiber Mode Multimode

Fiber Type OM5, LazrSPEED®

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)

Environmental Space Dual Rated LSZH/Riser

Regulatory Compliance/Certifications

Agency

ANATEL

ISO 9001:2015



Classification

Compliant

Designed, manufactured and/or distributed under this quality management system

Included Products

- 760233361 P-002-ZC-5G-F16LM – Fiber indoor cable, LazrSPEED® 1.6 mm Plenum Zipcord, Multimode OM5, Feet jacket marking, Lime green jacket color
- 860637378 – LazrSPEED® Elite LC Connector duplex for 1.6 mm Fiber, multimode