


UFXLCUC21

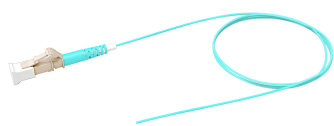

Ultra Low Loss (ULL) OM4 LC/UPC to Unconnectorized, 1.6 mm Simplex Fiber Pigtail, Low Smoke Zero Halogen (LSZH)

Product Classification

| | |
|-----------------------|--|
| Regional Availability | Asia Australia/New Zealand Europe Latin America Middle East /Africa North America |
| Portfolio | CommScope® |
| Product Type | Fiber pigtail, jacketed |
| Product Brand | SYSTIMAX ULL |
| Ordering Note | For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration |


General Specifications

| | |
|------------------------|--------|
| Color, boot A | Aqua |
| Color, connector A | Beige |
| Interface, Connector A | LC/UPC |
| Jacket Color | Aqua |
| Total Fibers, quantity | 1 |

Dimensions

| | |
|----------------------------------|-------------------|
| Cable Assembly Length Range (m) | 1 – 61 |
| Cable Assembly Length Range (ft) | 2 – 200 |
| Diameter Over Jacket | 1.6 mm 0.063 in |

Ordering Tree

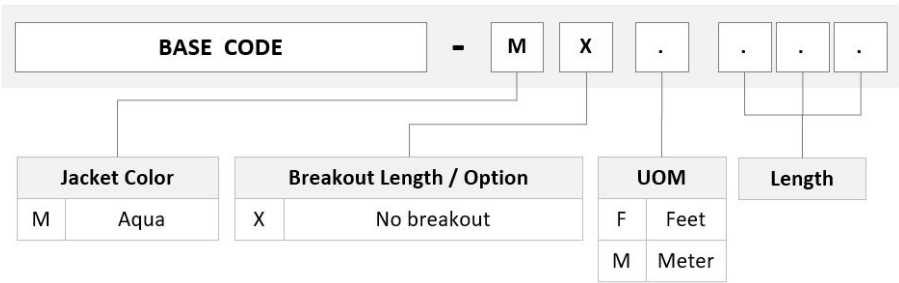

UFXLCUC21

Mechanical Specifications

Cable Retention Strength, maximum 11.24 lb @ 0 ° | 4.40 lb @ 90 °

Optical Specifications

Fiber Mode Multimode
Fiber Type OM4, LazrSPEED®

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)
Environmental Space Dual Rated LSZH/Riser

Regulatory Compliance/Certifications

| Agency | Classification |
|---------------|--|
| ANATEL | Compliant |
| ISO 9001:2015 | Designed, manufactured and/or distributed under this quality management system |



Included Products

- | | | |
|---------------------|---|---|
| 760164152 | – | Fiber Indoor Cable, LazrSPEED® 1.6mm Low Smoke Zero Halogen Riser, 1-fiber Simplex, |
| N-001-SP-5K-F16AQ/E | | Multimode OM4, Feet jacket marking, Aqua jacket color, Eca Flame Rating |
| 860637378 | – | LazrSPEED® Elite LC Connector duplex for 1.6 mm Fiber, multimode |