

Ultra Low Loss (ULL) Singlemode MPO12 (Unpinned) to MPO12 (Pinned), Fiber Trunk Cable Assembly, 432-Fiber, Rollable Ribbon Central Tube, Low Smoke Zero Halogen/Riser

## Product Classification

Regional Availability	Asia   Australia/New Zealand   Europe   Latin America   Middle East /Africa   North America
Portfolio	CommScope®
Product Type	Fiber trunk cable assembly
Product Brand	SYSTIMAX ULL
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative   For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration

## General Specifications

Color, boot A	Black
Color, boot B	Black
Color, connector A	Green
Color, connector B	Green
Construction Type	Rollable ribbon
Fibers per Subunit, quantity	12
Furcation Color	Yellow
Interface, Connector A	MPO-12/APC Female
Interface, Connector B	MPO-12/APC Male
Jacket Color	Yellow
Polarity	Method B Enhanced (ULL)
Total Fibers, quantity	432


## Dimensions

Breakout Length	33 in
-----------------	-------

# UJGMPMXRV

Cable Assembly Length Range (m)	3 – 999
Cable Assembly Length Range (ft)	10 – 999

## Ordering Tree

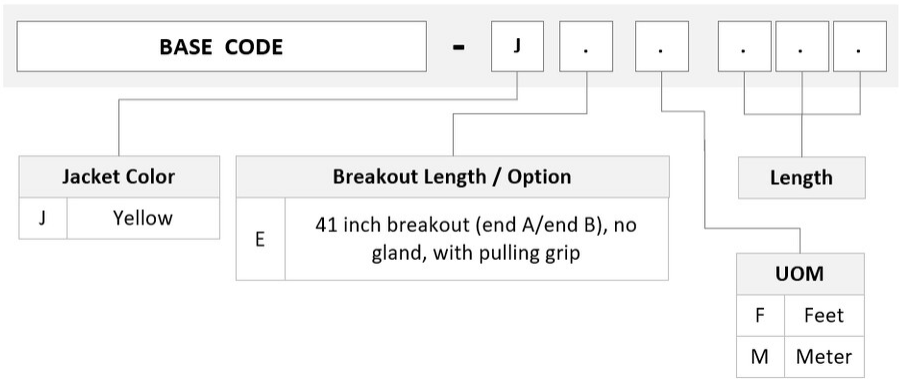

## Mechanical Specifications

Cable Retention Strength, maximum	11.24 lb @ 0 °   4.40 lb @ 90 °
-----------------------------------	---------------------------------

## Optical Specifications

Fiber Mode	Singlemode
Fiber Type	G.657.A2, TeraSPEED®

## Environmental Specifications

Operating Temperature	-10 °C to +60 °C (+14 °F to +140 °F)
Environmental Space	Dual Rated LSZH/Riser

## Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant



# UJGMPMXRV

---

## Included Products

760240984	–	Fiber indoor cable, All-Dielectric, LSZH/Riser-Rated, Gel-Free, Central Tube Rollable Ribbon, 432
N-432-CN-RR-F12YL/8G/99G/C		fiber, Singlemode G.657.A2/B2, Feet jacket marking, Yellow jacket color, Cca flame rating
860638317	–	MPO12, ULTRA LOW LOSS, MALE, Singlemode, GREEN, 3mm
860638318	–	MPO12, ULTRA LOW LOSS, FEMALE, Singlemode, GREEN, 3mm