


AGGMXMPAG

Base Product

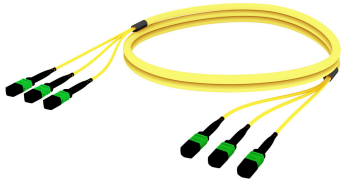

Singlemode MPO12 (Pinned) to MPO12 (Unpinned), Fiber Trunk Cable Assembly, 36-Fiber, Method A, Plenum

Product Classification

Regional Availability

Asia | Australia/New Zealand | China | Europe | India | Latin America | Middle East/Africa | North America

Portfolio

CommScope®

Product Type

Fiber trunk cable assembly

Ordering Note

For lengths greater than 999 ft (304 m), orders must be in meters | Minimum length may vary based on cable configuration

General Specifications

Color, boot A

Black

Color, connector A

Green

Color, boot B

Black

Color, connector B

Green

Construction Type

Stranded

Furcation Color

Yellow

Interface, Connector A

MPO-12/APC Male

Interface, Connector B

MPO-12/APC Female

Jacket Color

Yellow

Polarity

Method A

Fibers per Subunit, quantity

12

Total Fibers, quantity

36

Dimensions

Cable Assembly Length Range (m)

3 – 999

Cable Assembly Length Range (ft)

10 – 999

Ordering Tree

AGGMXMPAG



Mechanical Specifications

Cable Retention Strength, maximum 11.24 lb @ 0° | 4.40 lb @ 90°

Optical Specifications

Fiber Mode Singlemode

Fiber Type G.652.D | G.657.A2, TeraSPEED®

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)

Environmental Space Indoor | Plenum

Regulatory Compliance/Certifications

Agency	Classification
ANATEL	Compliant
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted



Included Products

760237966	–	Plenum MPO Trunk Cable, 36 fiber multi-unit with 12 fiber subunits
P-036-MP-8G1-F12YL		
860638317	–	MPO12, ULTRA LOW LOSS, MALE, Singlemode, GREEN, 3mm

AGGMXMPAG

860638318

– MPO12, ULTRA LOW LOSS, FEMALE, Singlemode, GREEN, 3mm