


FNXLCUCAD

Base Product

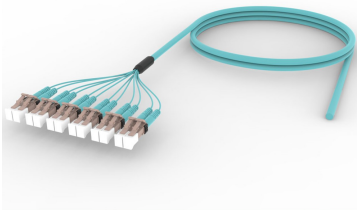

OM4 LC/UPC to Unconnectorized 12-Fiber InstaPATCH® 360 Ruggedized Fanout Cable, Low Smoke Zero Halogen

Product Classification

Regional Availability

Asia | Australia/New Zealand | China | Europe | India | Latin America | Middle East/Africa | North America

Portfolio

CommScope®

Product Type

Ruggedized fanout

Product Brand

SYSTIMAX InstaPATCH® 360

Ordering Note

For lengths greater than 999 ft (304 m), orders must be in meters | Minimum length may vary based on cable configuration | Not available in the United States or Canada

General Specifications

Color, boot A

Aqua

Color, connector A

Beige

Construction Type

Stranded

Furcation Color

Aqua

Interface, Connector A

LC/UPC

Interface, Connector B

Unterminated

Jacket Color

Aqua

Fibers per Subunit, quantity

12

Total Fibers, quantity

12

Dimensions

Cable Assembly Length Range (m)

3 – 305

Cable Assembly Length Range (ft)

8 – 999

Ordering Tree

FNXLCUCAD



Mechanical Specifications

Cable Retention Strength, maximum 11.24 lb @ 0 ° | 4.40 lb @ 90 °

Optical Specifications

Fiber Mode Multimode

Fiber Type OM4, LazrSPEED®

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)

Environmental Space Dual Rated LSZH/Riser | Indoor

Regulatory Compliance/Certifications

Agency	Classification
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system

Included Products

- 460125198 – Pre-Radiused LC Connector duplex for 1.6 mm Fiber, multimode
- N-012-MP-5K-F12 – Fiber Indoor Cable, LazrSPEED® Low Smoke Zero Halogen Riser MPO Trunk Cable, 12 fiber, Gel-free, Multimode OM4, Dca Flame Rating, Feet jacket marking