


# UNXMPLUCM

## Base Product

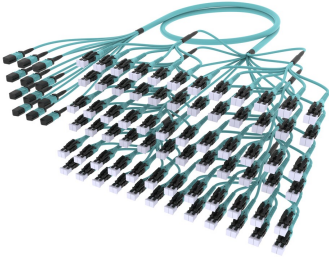

Ultra Low Loss ULL LazrSPEED® 550 MPO(Unpinned) to LC/UPC  
Uniboot Ruggedized fanout Cable, 144-Fiber, LSZH, 12 fiber PmP 2.0 mm  
Dca

## Product Classification

|                              |  |
|------------------------------|--|
| <b>Regional Availability</b> | Asia   Australia/New Zealand   Europe   Latin America   Middle East/Africa   North America   |
| <b>Portfolio</b>             | CommScope®   |
| <b>Product Type</b>          | Ruggedized fanout  |
| <b>Product Brand</b>         | SYSTIMAX ULL   |
| <b>Ordering Note</b>         | For additional jacket colors, please contact a CommScope Sales Representative   For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration |

## General Specifications

|                                       |                         |
|---------------------------------------|-------------------------|
| <b>Color, boot A</b>                  | Black                   |
| <b>Color, connector A</b>             | Black                   |
| <b>Color, boot B</b>                  | Blue                    |
| <b>Color, connector B</b>             | Black                   |
| <b>Construction Type</b>              | Stranded                |
| <b>Furcation Color</b>                | Aqua                    |
| <b>Interface, Connector A</b>         | MPO-12/UPC Female       |
| <b>Interface, Connector B</b>         | LC/UPC                  |
| <b>Interface Feature, connector B</b> | Uniboot                 |
| <b>Jacket Color</b>                   | Aqua                    |
| <b>Polarity</b>                       | Method B Enhanced (ULL) |
| <b>Fibers per Subunit, quantity</b>   | 12                      |
| <b>Total Fibers, quantity</b>         | 144                     |

## Dimensions


|  |         |
|--|---------|
| <b>Cable Assembly Length Range (m)</b> | 3 – 999 |
|--|---------|

# UNXMPLUCM

Cable Assembly Length Range (ft)

10 – 999

## Ordering Tree

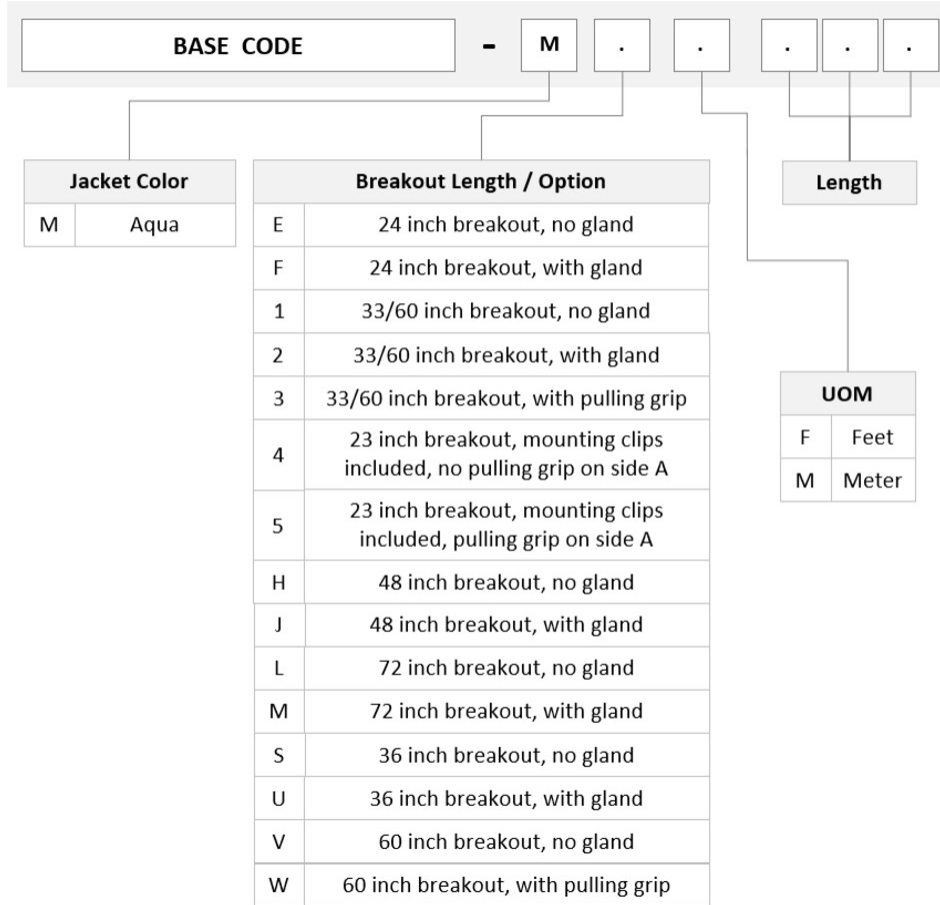

## Optical Specifications

|                   |                 |
|-------------------|-----------------|
| <b>Fiber Mode</b> | Multimode       |
| <b>Fiber Type</b> | OM4, LazrSPEED® |

## Environmental Specifications

|   |                                      |
|---|--------------------------------------|
| <b>Operating Temperature</b>                        | -10 °C to +60 °C (+14 °F to +140 °F) |
| <b>EN50575 CPR Cable EuroClass Fire Performance</b> | Dca                                  |
| <b>Environmental Space</b>                          | Dual Rated LSZH/Riser   Indoor       |

## Regulatory Compliance/Certifications

# UNXMPLUCM

---

| Agency        | Classification   |
|---------------|--|
| CHINA-ROHS    | Below maximum concentration value  |
| ISO 9001:2015 | Designed, manufactured and/or distributed under this quality management system   |
| REACH-SVHC    | Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a> |
| ROHS          | Compliant  |
| UK-ROHS       | Compliant  |



## Included Products

|                                      |   |   |
|--------------------------------------|---|---|
| 760222869<br>N-144-MP-5K-F12AQ/20T/D | - | Fiber indoor cable, LazrSPEED® Low Smoke Zero Halogen Riser MPO Trunk, 144 fiber multi-unit with 12 fiber 2.0mm subunits, Gel-free, Multimode OM4, Feet jacket marking, Aqua jacket color, Dca flame rating |
| 860658161                            | - | 2.0 mm LC/UPC Uniboot GEN 1.5, Aqua   |
| 860659012                            | - | MPO12, ULL, FEMALE, OM3/4, AQUA, 2MM  |