



Ultra Low Loss (ULL) OM5 MPO8 (Unpinned) to MPO8 (Unpinned), Polarity and Gender Changeable, Fiber Extension Cable Assembly, 8-Fiber, Plenum

Product Classification

Regional Availability	Asia Australia/New Zealand Europe Latin America Middle East /Africa North America
Portfolio	CommScope®
Product Type	Fiber array cable assembly
Product Brand	SYSTIMAX ULL
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration

General Specifications

Connector A, quantity	1
Color, boot A	Gray
Color, connector A	Lime green
Connector B, quantity	1
Color, boot B	Gray
Color, connector B	Lime green
Construction Type	Stranded
Interface, Connector A	MPO-08/UPC Female
Interface Feature, connector A	Gender changeable
Interface, Connector B	MPO-08/UPC Female
Interface Feature, connector B	Gender changeable
Jacket Color	Lime green
Polarity	Method B Enhanced (ULL)
Total Fibers, quantity	8

Dimensions


Cable Assembly Length Range (m)	1 – 305
---------------------------------	---------

UQVQFQFJ8

Cable Assembly Length Range (ft)

1 – 999

Ordering Tree

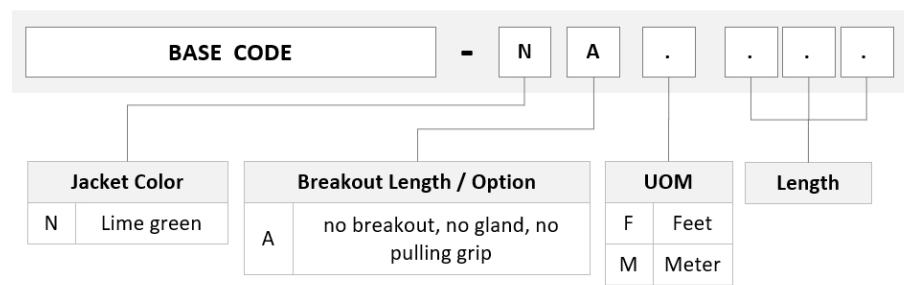

Optical Specifications

Fiber Mode

Multimode

Fiber Type

OM5, LazrSPEED®

Environmental Specifications

Operating Temperature

-10 °C to +60 °C (+14 °F to +140 °F)

Environmental Space

Indoor | Plenum

Regulatory Compliance/Certifications

Agency

ANATEL

ISO 9001:2015

Classification

Compliant

Designed, manufactured and/or distributed under this quality management system



Included Products

- 760216523

P-012-MP-5G-F30LM

860642493
- Fiber indoor cable, LazrSPEED® Plenum MPO Light Duty for Patchcords, 12 fiber, Multimode OM5, Feet jacket marking, Lime green jacket color

-

LazrSPEED® Elite MTP Pro Female 8 Fiber Connector, lime green