

# AGXMXMXAD

---

## Base Product



OM4 MPO12 (Pinned) to MPO12 (Pinned), Fiber Trunk Cable Assembly, 12-Fiber, Method A, Plenum

## Product Classification

|                              |                                                                                                                          |
|------------------------------|--------------------------------------------------------------------------------------------------------------------------|
| <b>Regional Availability</b> | Asia   Australia/New Zealand   China   Europe   India   Latin America   Middle East/Africa   North America               |
| <b>Portfolio</b>             | CommScope®                                                                                                               |
| <b>Product Type</b>          | Fiber trunk cable assembly                                                                                               |
| <b>Ordering Note</b>         | For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration |

## General Specifications


|                                     |                 |
|-------------------------------------|-----------------|
| <b>Color, boot A</b>                | Black           |
| <b>Color, connector A</b>           | Aqua            |
| <b>Color, boot B</b>                | Black           |
| <b>Color, connector B</b>           | Aqua            |
| <b>Construction Type</b>            | Stranded        |
| <b>Furcation Color</b>              | Aqua            |
| <b>Interface, Connector A</b>       | MPO-12/UPC Male |
| <b>Interface, Connector B</b>       | MPO-12/UPC Male |
| <b>Jacket Color</b>                 | Aqua            |
| <b>Polarity</b>                     | Method A        |
| <b>Fibers per Subunit, quantity</b> | 12              |
| <b>Total Fibers, quantity</b>       | 12              |

## Dimensions

|                                         |          |
|-----------------------------------------|----------|
| <b>Cable Assembly Length Range (m)</b>  | 3 – 999  |
| <b>Cable Assembly Length Range (ft)</b> | 10 – 999 |

# AGXMXMXAD

## Ordering Tree

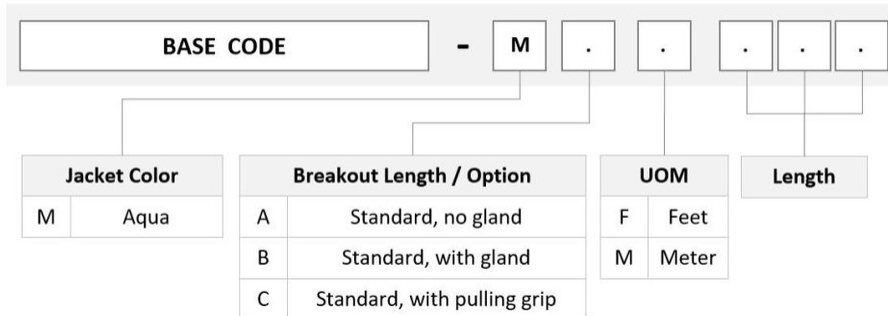

## Mechanical Specifications

**Cable Retention Strength, maximum** 11.24 lb @ 0 ° | 4.40 lb @ 90 °

## Optical Specifications

**Fiber Mode** Multimode

**Fiber Type** OM4, LazrSPEED®

## Environmental Specifications

**Operating Temperature** -10 °C to +60 °C (+14 °F to +140 °F)

**Environmental Space** Indoor | Plenum

## Regulatory Compliance/Certifications

| Agency        | Classification                                                                                                                 |
|---------------|--------------------------------------------------------------------------------------------------------------------------------|
| ANATEL        | Compliant                                                                                                                      |
| CHINA-ROHS    | Above maximum concentration value                                                                                              |
| ISO 9001:2015 | Designed, manufactured and/or distributed under this quality management system                                                 |
| REACH-SVHC    | Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a> |
| ROHS          | Compliant/Exempted                                                                                                             |
| UK-ROHS       | Compliant/Exempted                                                                                                             |



## Included Products

# AGXMXMXAD

---

- 760186403  
P-012-MP-5K-F12BL – Fiber indoor cable, LazrSPEED® Plenum for MPO Trunks, 12 fiber, Multimode OM4, Feet jacket marking, Blue jacket color
- 860366228 – MPO12, ULTRA LOW LOSS, MALE, OM3/4, AQUA, 3mm