


AJX2X2PBH

Base Product

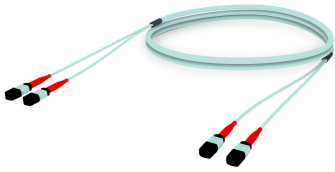

OM4 MPO24 (Pinned) to MPO24 (Unpinned), Fiber Trunk Cable Assembly, 48-Fiber, Method A, Low Smoke Zero Halogen

Product Classification

Regional Availability

Asia | Australia/New Zealand | China | Europe | India | Latin America | Middle East/Africa | North America

Portfolio

CommScope®

Product Type

Fiber trunk cable assembly

Ordering Note

For lengths greater than 999 ft (304 m), orders must be in meters | Minimum length may vary based on cable configuration

General Specifications

Color, boot A

Red

Color, connector A

Aqua

Color, boot B

Red

Color, connector B

Aqua

Construction Type

Stranded

Furcation Color

Aqua

Interface, Connector A

MPO-24/UPC Male

Interface, Connector B

MPO-24/UPC Female

Jacket Color

Aqua

Polarity

Method A

Fibers per Subunit, quantity

24

Total Fibers, quantity

48

Dimensions

Cable Assembly Length Range (m)

3 – 999

Cable Assembly Length Range (ft)

10 – 999

Ordering Tree

AJX2X2PBH



Mechanical Specifications

Cable Retention Strength, maximum 11.24 lb @ 0 ° | 4.40 lb @ 90 °

Optical Specifications

Fiber Mode Multimode
Fiber Type OM4, LazrSPEED®

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)
Environmental Space Dual Rated LSZH/Riser | Indoor

Regulatory Compliance/Certifications

AJX2X2PBH

Agency	Classification
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted



Included Products

760249075 N-048-MP-5K-F24AQ/30T/B2	-	Fiber indoor cable, LazrSPEED® Low Smoke Zero Halogen Riser MPO Trunk, 48 fiber with 24-fiber, 3.0 mm subunits, Multimode OM4, Feet jacket marking, Aqua jacket color, B2ca flame rating
860662277	-	MPO24,FEMALE,OM3/4,AQUA,3.0MM
860662278	-	MPO24,MALE,OM3/4,AQUA,3.0MM