


FEWL7L721

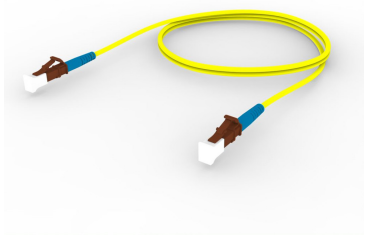

Singlemode LC/UPC Keyed Brown to LC/UPC Keyed Brown Fiber Patch Cord, 1.6 mm Simplex, Riser

Product Classification

Regional Availability	Asia Australia/New Zealand Europe Latin America Middle East /Africa North America
Portfolio	CommScope®
Product Type	Fiber patch cord, simplex
Product Brand	SYSTIMAX InstaPATCH® 360
Ordering Note	For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration

General Specifications

Color, boot A	Blue
Color, boot B	Blue
Color, connector A	Brown
Color, connector B	Brown
Connector A, quantity	1
Connector B, quantity	1
Interface, Connector A	LC/UPC
Interface Feature, connector A	Keyed
Interface, Connector B	LC/UPC
Interface Feature, connector B	Keyed
Jacket Color	Yellow
Polarity	Method B
Total Fibers, quantity	1


Dimensions

Cable Assembly Length Range (m)	1 – 61
Cable Assembly Length Range (ft)	2 – 200

FEWL7L721

Diameter Over Jacket1.6 mm | 0.063 in

Ordering Tree

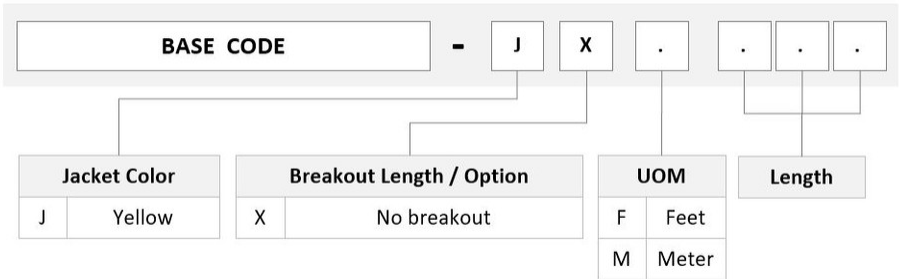

Mechanical Specifications

Cable Retention Strength, maximum11.24 lb @ 0 ° | 4.40 lb @ 90 °

Optical Specifications

Fiber ModeSinglemode

Fiber TypeG.652.D | G.657.A1, TeraSPEED®

Environmental Specifications

Operating Temperature-10 °C to +60 °C (+14 °F to +140 °F)

Environmental SpaceRiser

Regulatory Compliance/Certifications

AgencyClassification
ISO 9001:2015Designed, manufactured and/or distributed under this quality management system



Included Products

- 760102715 SFC-LCR-16-KBR – TeraSPEED® Pre-Radiused Keyed LC Connector for 1.6 mm Fiber, simplex Singlemode, brown
- R-001-SP-8W-F16 – TeraSPEED® 1.6mm Riser Simplex Cable