


9-1920523-1 | OCP-S2-15DASEN-XX

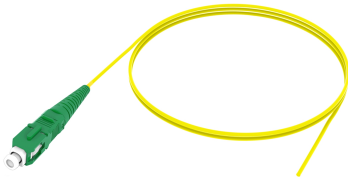

Fiber Optic Pigtail, Simplex, Singlemode, SC/APC to Stub, 0.9 mm diameter, 15 m

Product Classification

Regional Availability	EMEA
Product Type	Fiber pigtail, jacketed
Product Series	OCP


General Specifications

Connector A, quantity	1
Color, boot A	Green
Color, connector A	Green
Interface, Connector A	SC/APC
Jacket Color	Yellow
Total Fibers, quantity	1

Dimensions

Cord Length	15 m 49.213 ft
--------------------	------------------

Ordering Tree

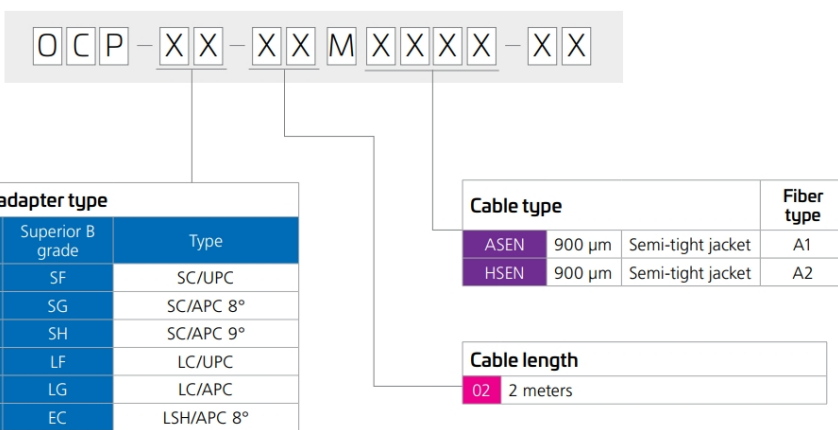

- Standard Configuration by default 900μm buffer
 buffer color : yellow
 250 μm color : natural or milky white

Optical Specifications

Fiber Mode	Singlemode
Fiber Type	G.657.A1, TeraSPEED®

Environmental Specifications

Environmental Space	Low Smoke Zero Halogen (LSZH)
----------------------------	-------------------------------

Packaging and Weights

Packaging quantity	1
---------------------------	---

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant/Exempted

