

F1B-PNRDR-24N



FSJ1-50A SureFlex® Jumper with interface types N Male Right Angle and 7-16 DIN Male Right Angle, 0.61 m

OBSOLETE

This product was discontinued on: November 30, 2023

Product Classification

Product Type	SureFlex® standard
Product Brand	HELIAX® SureFlex®
Product Series	FSJ1-50A

General Specifications

Attachment, Connector A	Field attachment
Body Style, Connector A	Right angle
Body Style, Connector B	Right angle
Interface, Connector A	N Male
Interface, Connector B	7-16 DIN Male
Orientation	0°
Specification Sheet Revision Level	A

Dimensions


Length	0.61 m 2.001 ft
Nominal Size	1/4 in

VSWR/Return Loss

Frequency Band	VSWR	Return Loss (dB)
700–3000 MHz	1.33	17

Jumper Assembly Sample Label

F1B-PNRDR-24N

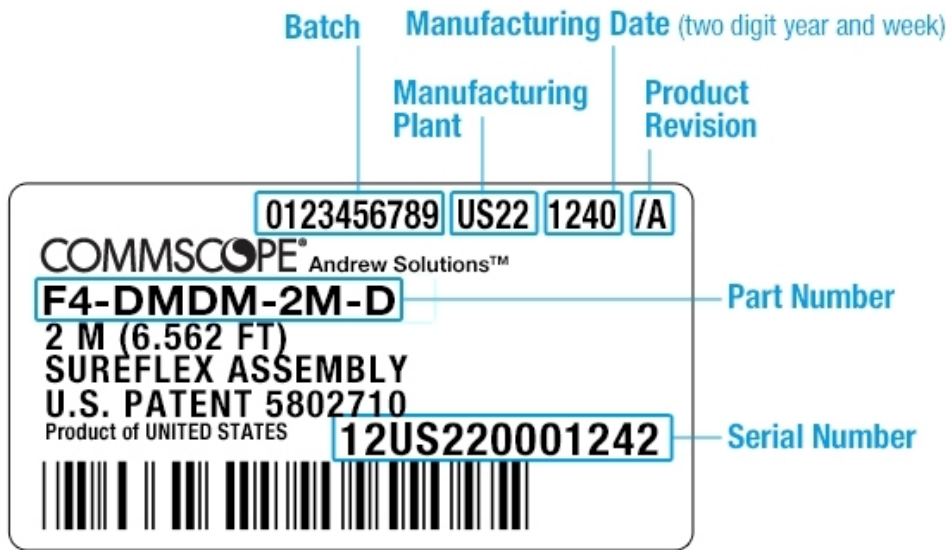

Environmental Specifications

Immersion Test Method

Meets IEC 60529:2001, IP68 in mated condition

Regulatory Compliance/Certifications

Agency

ISO 9001:2015

Classification

Designed, manufactured and/or distributed under this quality management system



Included Products

35422-33	-	Heat Treated FSJ1-50A, HELIAX® Superflexible Low Density Foam Coaxial Cable, corrugated copper, 1/4 in, black PE Jacket
35422-75	-	Heat Treated FSJ1RK-50B, HELIAX® Superflexible Foam Coaxial Cable, corrugated copper, 1/4 in, black non-halogenated, fire retardant polyolefin jacket
F1PNR-HC	-	Type N Male Right Angle for 1/4 in FSJ1-50A cable
F1TNR-HC	-	Type N Male Right Angle for 1/4 in FSJ1-50A cable
FSJ1-50A	-	FSJ1-50A, HELIAX® Superflexible Low Density Foam Coaxial Cable, corrugated copper, 1/4 in, black PE jacket
FSJ1RK-50A	-	FSJ1-50A, HELIAX® Superflexible Foam Coaxial Cable, corrugated copper, 1/4 in, black non-halogenated, fire retardant polyolefin jacket, B2ca s1a dO a1 Compliant