

# L4-PDMDM-6

---

LDF4-50A Jumper with interface types 7-16 DIN Male and 7-16 DIN Male, 1.829 m



## Product Classification

**Product Type** SureFlex® standard

**Product Series** LDF4-50A

## General Specifications

**Body Style, Connector A** Straight

**Body Style, Connector B** Straight

**Interface, Connector A** 7-16 DIN Male

**Interface, Connector B** 7-16 DIN Male

**Specification Sheet Revision Level** A

## Dimensions

**Length** 1.829 m | 6.001 ft

**Nominal Size** 1/2 in


## Electrical Specifications

**DTF, Connector A** -32 dB

**DTF, Connector B** -32 dB

## Jumper Assembly Sample Label

# L4-PDMDM-6

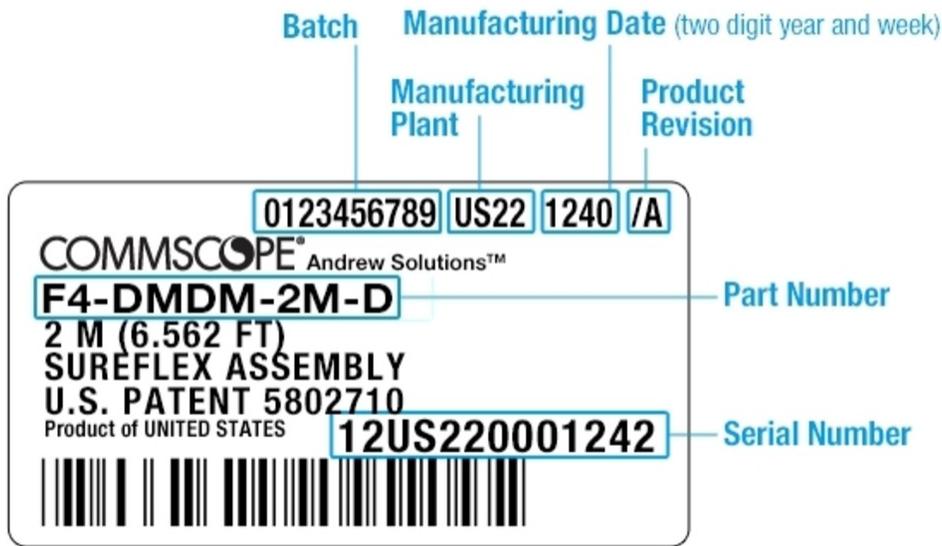

## Environmental Specifications

**Immersion Test Method** Meets IEC 60529:2001, IP68 in mated condition

## Regulatory Compliance/Certifications

Agency	Classification
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system



## Included Products

- |           |                                                                                                                                            |
|-----------|--------------------------------------------------------------------------------------------------------------------------------------------|
| L4TDM-PS  | - 7-16 DIN Male Positive Stop™ for 1/2 in LDF4-50A cable                                                                                   |
| L4TDM-PSA | - 7-16 DIN Male Positive Stop™ for 1/2 in AL4RPV-50, LDF4-50A, HL4RPV-50 cable                                                             |
| LDF4-50A  | - LDF4-50A, HELIAX® Low Density Foam Coaxial Cable, corrugated copper, 1/2 in, black PE jacket (Halogen free jacketing non-fire-retardant) |