


FPC2-SPLC-15M

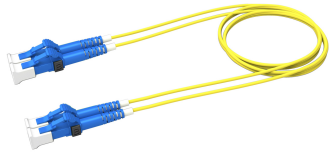

Fiber Optic Patch Cord, Duplex, Singlemode, LC/UPC to LC/UPC, yellow, 15 m

Product Classification

Regional Availability	Latin America North America
Product Type	Fiber patch cord, duplex
Product Series	FPC2

General Specifications

Connector A, quantity	2
Color, boot A	Blue
Color, connector A	Blue
Connector B, quantity	2
Color, boot B	Blue
Color, connector B	Blue
Interface, Connector A	LC/UPC
Interface, Connector B	LC/UPC
Jacket Color	Yellow
Total Fibers, quantity	2

Dimensions

Cord Length	15 m 49.213 ft
Diameter Over Jacket	2 mm 0.079 in

Optical Specifications

Fiber Mode	Singlemode
Fiber Type	OS1
Insertion Loss, maximum, connector A	0.3 dB
Insertion Loss, maximum, connector B	0.3 dB
Return Loss, minimum, connector A	55 dB
Return Loss, minimum, connector B	55 dB

FPC2-SPLC-15M

Environmental Specifications

Environmental Space Riser

Packaging and Weights

Packaging quantity 1

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant

