

TFAN50-14

ION®-B Series Low Power Remote Unit for UHF



OBSOLETE

This product was discontinued on: August 30, 2015

Product Classification


Product Type	Remote unit
Product Brand	ION®-B

General Specifications

Note	Detailed Product Specifications are available. Please contact your local CommScope representative.
Power Class	Low

Dimension Drawing

TFAN50-14

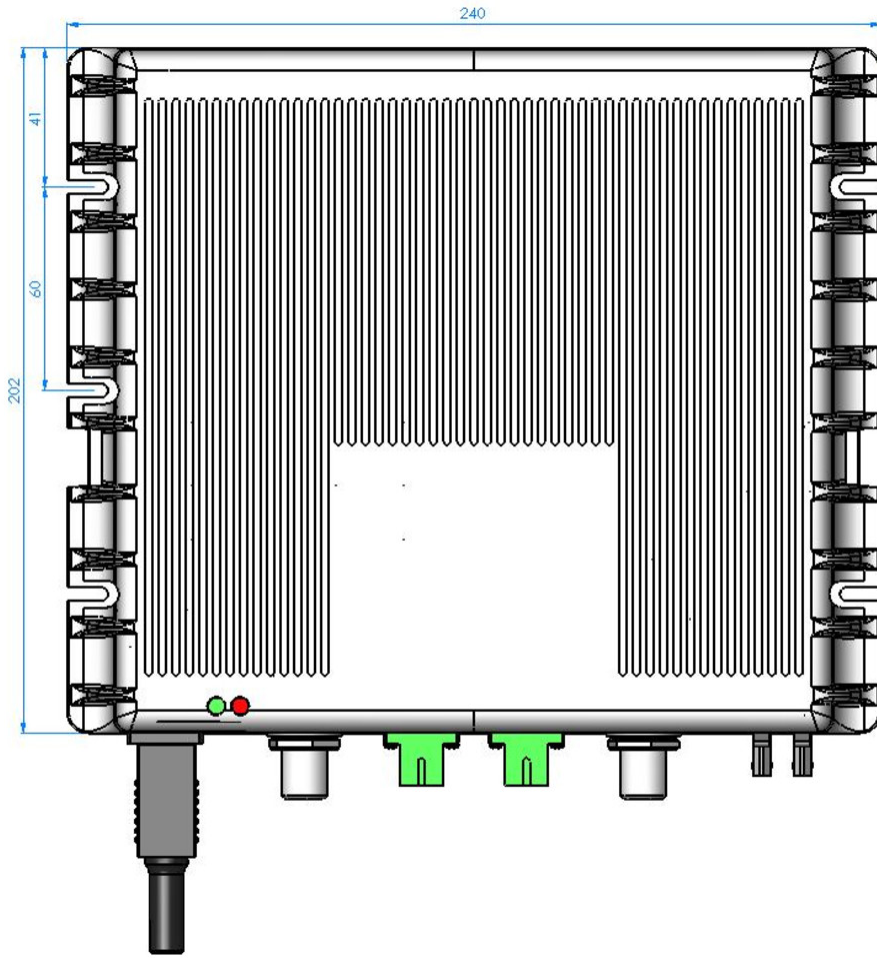

Electrical Specifications

Impedance	50 ohm
License Band	UHF
Voltage Range	85 to 265 Vac

Electrical Specifications, Rx (Uplink)

Operating Frequency Band	380 – 580 MHz (UHF)
---------------------------------	---------------------

Electrical Specifications, Tx (Downlink)

Operating Frequency Band	380 – 580 MHz (UHF)
---------------------------------	---------------------

Regulatory Compliance/Certifications

TFAN50-14

Agency

Classification

CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted

