

# TFBM26-3

---

## ION®-B Series Extension Unit for WiMAX 2600



**OBSOLETE**

### Product Classification

**Product Type** Extension unit

**Product Brand** ION®-B


### General Specifications

**Note** Detailed Product Specifications are available. Please contact your local CommScope representative.

**Power Type** Medium

### Dimension Drawing

# TFBM26-3

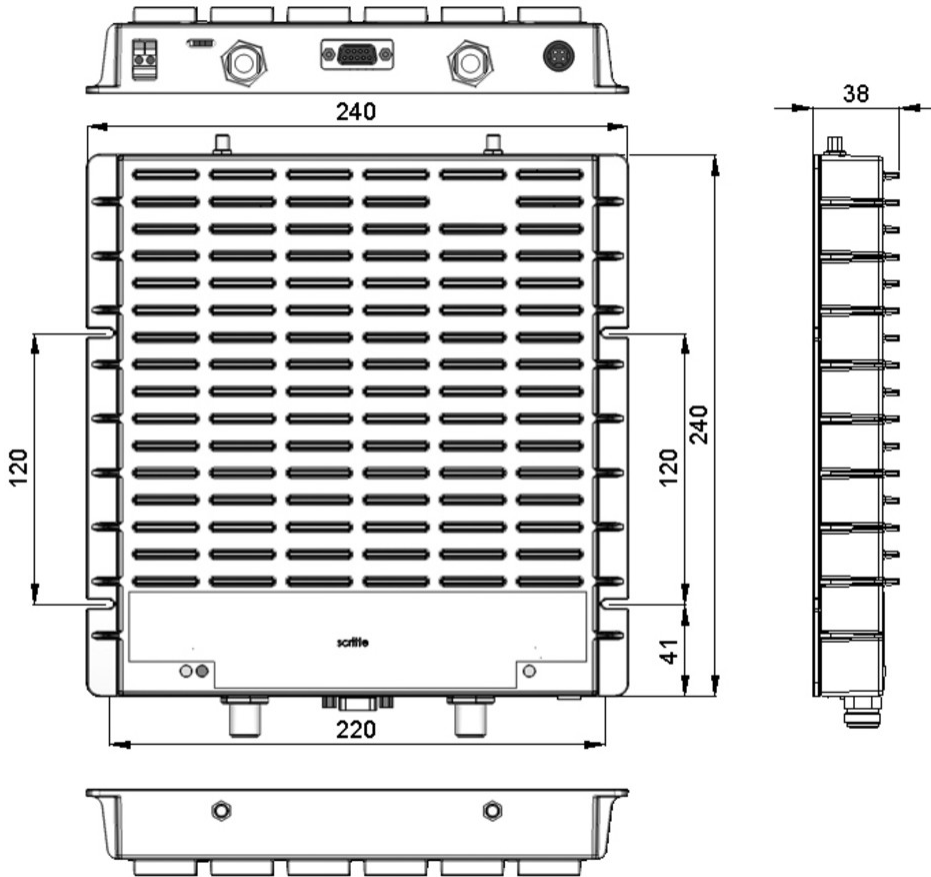

## Electrical Specifications



<b>Impedance</b>	50 ohm
<b>License Band</b>	WiMAX 2600
<b>Voltage Range</b>	-60 to -36 Vdc

## Electrical Specifications, Tx (Downlink)

<b>Operating Frequency Band</b>	2496 – 2690 MHz (WiMAX 2600)
---------------------------------	------------------------------

## Cabling Drawing

# TFBM26-3

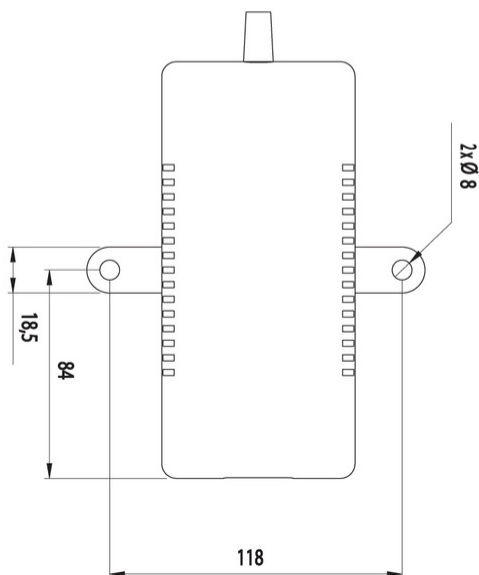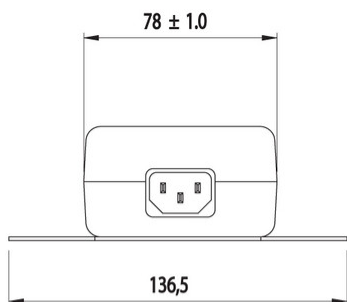

## Regulatory Compliance/Certifications

### Agency

ISO 9001:2015



### Classification

Designed, manufactured and/or distributed under this quality management system

## Included Products

TPSN3/28-80 – Power Supply Adapter ION®-B Series Remote Units, 80 W

# TPSN3/28-80

## Power Supply Adapter ION®-B Series Remote Units, 80 W



### Product Classification

**Product Type**

Power adapters

**Product Brand**


ION®-B

### General Specifications

**Note**

Detailed Product Specifications are available. Please contact your local CommScope representative.

### Dimension Drawing

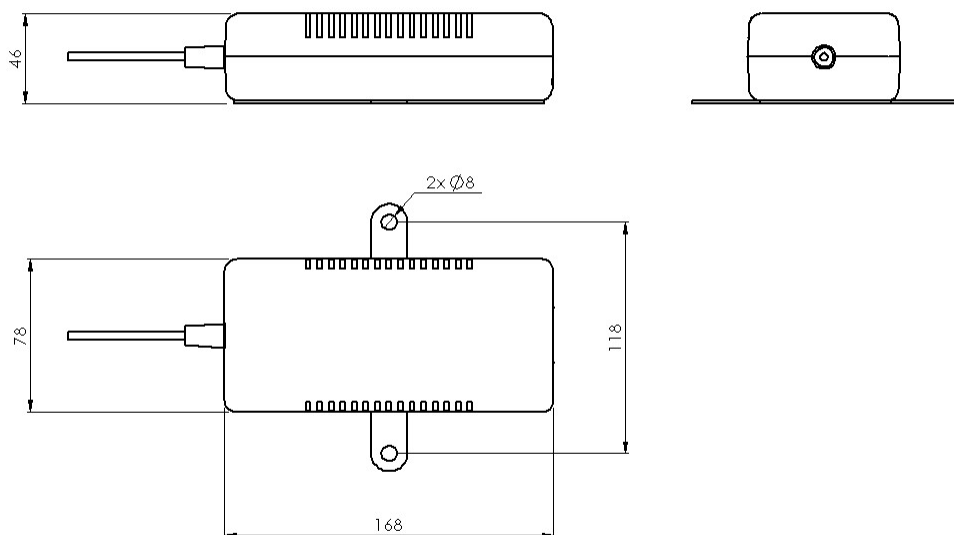

# TPSN3/28-80

---

## Electrical Specifications

**Output Power, maximum**

80 W

## Regulatory Compliance/Certifications

**Agency**

ISO 9001:2015

**Classification**

Designed, manufactured and/or distributed under this quality management system

