


6600D-4

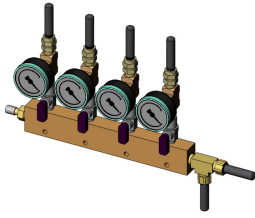

4-port Distribution Manifold, wall mountable, 0–15.0 psig, 25 ft of tubing per port

Product Classification

Product Type Manifold

General Specifications

Distribution System Manifold
Mounting Wall
Port Count 4
Port Type 3/8 in PE tube
Regulated Output Pressure, maximum 103.421 kPa | 15 psig
Regulated Output Pressure, minimum 0 kPa | 0 psig

Dimensions

Product Height 165.1 mm | 6.5 in
Product Width 279.4 mm | 11 in
Product Depth 63.5 mm | 2.5 in

Environmental Specifications

Operating Temperature +1 °C to +40 °C (+33 °F to +104 °F)

Packaging and Weights

Height, packed 406.4 mm | 16 in
Width, packed 177.8 mm | 7 in
Depth, packed 558.8 mm | 22 in
Included 3/8 in polyethylene tubing | 90° elbow fitting | Cable tie | Male connector fitting | PTFE tape
Weight, gross 3.63 kg | 8.003 lb
Weight, net 2.76 kg | 6.085 lb

6600D-4

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant

